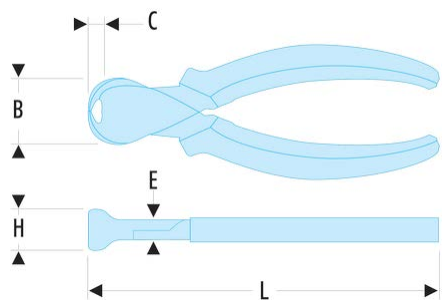


**190.20CPESLS 190.CPESLS - End cutters****Description :**

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The crimped "rotating" cable solution, selected and tested by FACOM, maintains user ergonomics.
- Cutting edges designed to cleanly cut all types of wire: piano wire, hard and soft wires (max. 200 kg/mm<sup>2</sup>).
- Long lever arm, offset pivot for minimum cutting effort.
- High durability Chrome-Molybdenum-Vanadium steel, very hard cutting edges 61/63 HRc.
- Ergonomic grips resistant to chemical agents.
- Removable return spring.
- Finish: chromed.

---

**B [mm]:** 31

---

**C [mm]:** 7,5

---

**d maxi [mm]:** 2,0

---

**E [mm]:** 13,5

---

**H [mm]:** 29

---

**L [mm]:** 200

---

**[g]:** 365

---