
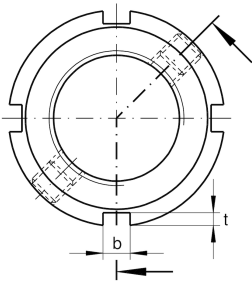


ZM130

Precision locknut

Precision locknut ZM, accessory ZM..

Technical information

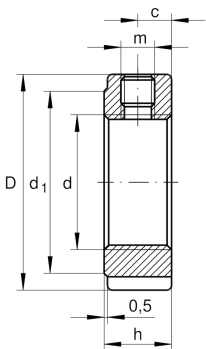

Main Dimensions & Performance Data

d	M130X2	Thread
D	165 mm	Outside diameter
h	24 mm	Height
M _A	20 Nm	Mounting torque set screw
F _{aB}	630,000 N	Breaking load, axial
M _L	700 Nm	Breakawag
M _{AL}	550 Nm	Mounting torque reference
M _M	84.3 kg*cm ²	Mass moment of inertia
≈m	1.51 kg	Weight

Dimensions

d ₁	149 mm	Plant diameter outside
t	5 mm	Hight retaining slot
b	12 mm	Width retaining slot
c	12 mm	Distance bore
m	M10	Threaded - threaded pin