


Blue Elastic Rubber Trolley Wheel 100mm, 150kg

Elastic Rubber-tyred wheel

PRODUCT

Article number **571-401-100L12**

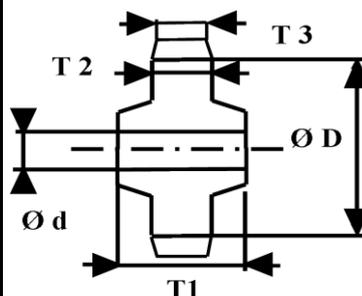

Product Details

Wheel Rim : very thick black polyamide.
Tyre : solid, black bonded elastic rubber tyre.
Hub : symmetrical with plain bore.

Specifications

Wheel Diameter - $\varnothing D \pm 1\%$	100 mm
Hub Type	Plain
Hub Length T1	44 mm ± 1
Width of Tread T2	36 mm ± 1
Width of Tread-on floor T3	36 mm ± 1
Axle Hole $\varnothing d$	$\varnothing 12$ mm
Hardness of tread A ± 4	A 70 Shore
Load capacity	150 Kg
Temperature	-20 / +60 °C
Weight	0,28 kg

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
Resilient with a low starting effort.
Does not leave scratches or other marks on surfaces.
Reduces shock and vibration.
Quiet in use and high wear resistance.
Suitable for industrial floors and also all interior floors.