
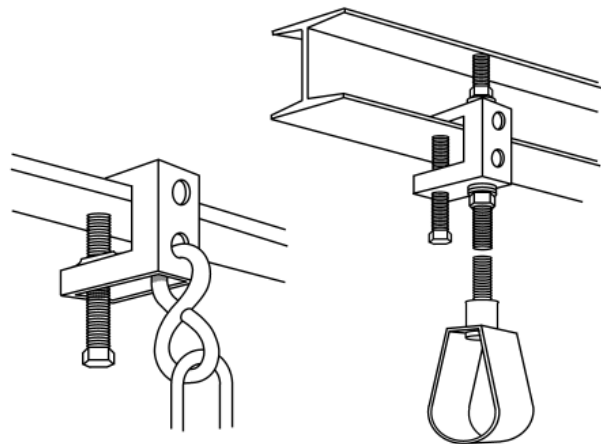


## Datasheet

# Girder Threaded Rod Clamp, maximum load 45kg, 18mm

RS Stock number [291076](#)

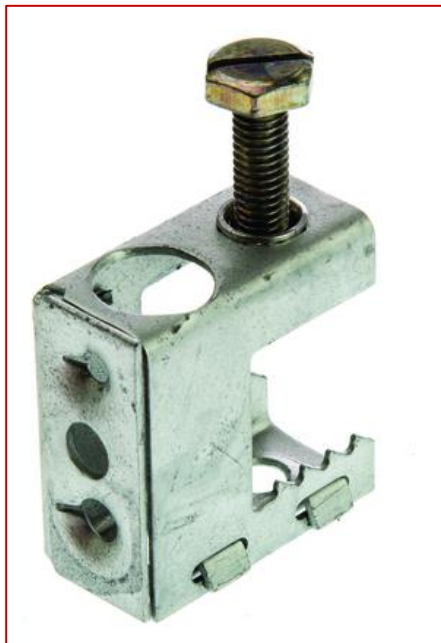


### Description

Zinc silver coloured sacrificial coating (Z600+), enhanced by an application of waterproof topcoat giving a corrosion resistance of more than 600 hours, for use in indoor and outdoor humid and mildly corrosive environments. Coating is completely chromium free.

### Specification

- |                    |                 |
|--------------------|-----------------|
| • Flange Thickness | Maximum of 18mm |
| • Hole Diameter    | 12.7mm          |
| • Material         | Steel           |
| • Maximum Load     | 45kg            |

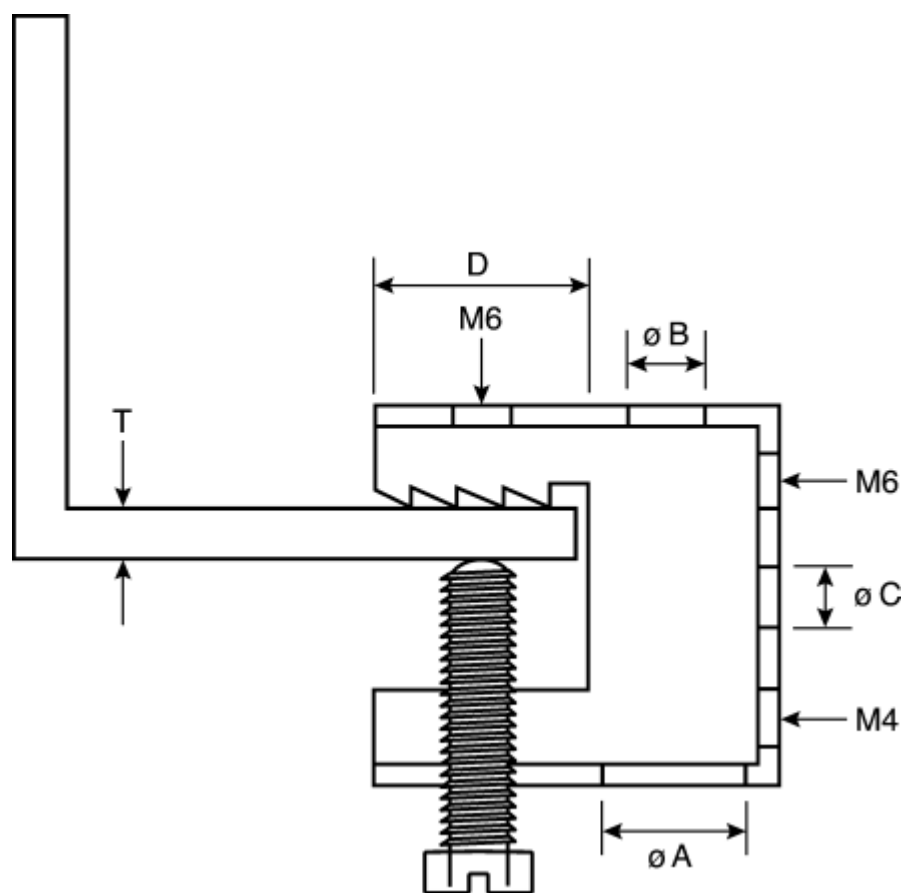

### Measurements

- T: Max 18mm
- $\varnothing A$ : 12.7mm
- $\varnothing B$ : 6.5mm
- $\varnothing C$ : 6.5mm
- D: 19.5mm
- Load: 45mm