


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			C	C_0	kN	r/min	kg	-	* - SKF Explorer bearing
25	52	15	14,8	7,8	0,335	28000	14000	0,13	6205-2Z *

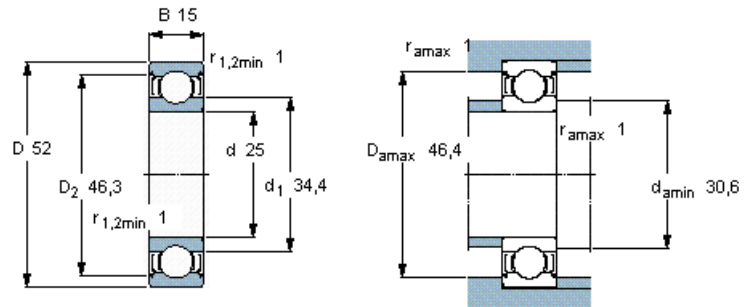

Calculation factors

k_r 0,025

f_0 14