 


# Kraftform Plus – Series 300

The right tool for every application

## 335 Slotted screwdriver



**Application:** Slotted screws

**Blade:** Round

**Design:** Chrome-plated, Lasertip

**Handle:** Kraftform with non-roll feature, multi-component

Code	mm	mm	mm	mm	mm	mm	mm	mm
0500806001 <sup>1)</sup>	0,4	2,0	60	70	2,5	5/64"	2 3/8"	10
0511000001 <sup>1)</sup>	0,4	2,5	60	70	2,5	3/32"	2 3/8"	10
0500807001 <sup>1)</sup>	0,4	2,5	75	70	2,5	3/32"	3"	10
0500808001 <sup>1)</sup>	0,5	3,0	150	81	4,0	1/8"	6"	10
0500809001 <sup>1)</sup>	0,5	3,0	200	81	4,0	1/8"	8"	5
05110001001 <sup>1)</sup>	0,5	3,0	80	81	3,0	1/8"	3 1/8"	10
05008015001	0,6	3,5	100	81	3,5	9/64"	4"	10
05110002001	0,6	3,5	125	81	3,5	9/64"	5"	10
05110003001	0,6	3,5	200	81	3,5	9/64"	8"	5
05110004001	0,8	4,0	100	98	4,0	5/32"	4"	10
05110005001	0,8	4,0	150	98	4,0	5/32"	6"	10
05110006001	0,8	4,0	200	98	4,0	5/32"	8"	5
05008027001 <sup>1)</sup>	0,8	4,0	300	98	4,0	5/32"	12"	2
05110007001	1,0	5,5	125	98	5,5	7/32"	5"	10
05008055001	1,0	5,5	150	98	5,5	7/32"	6"	10
05110008001	1,0	5,5	200	98	5,5	7/32"	8"	5
05008060001 <sup>1)</sup>	1,0	5,5	300	98	5,5	7/32"	12"	2
05008061001	1,2	6,0	100	105	6,0	5/16"	4"	10

1) without Lasertip

## 334 SK Slotted screwdriver



**Application:** Slotted screws

**Blade:** Hexagonal with bolster from 0.8 x 4.5

**Design:** Chrome-plated, Lasertip

**Handle:** Kraftform with non-roll feature, multi-component

Code	mm	mm	mm	mm	mm	mm	mm	mm	
05007670001	0,6	3,5	4	-	75	81	9/64"	3"	10
05007671001	0,8	4,0	4	-	90	81	5/32"	3 1/2"	10
05007672001	0,8	4,5	5	8	90	98	0,178"	3 1/2"	10
05007673001	1,0	5,5	6	10	100	98	7/32"	4"	10
05007674001	1,2	6,5	6	10	125	105	1/4"	5"	10
05007675001	1,2	7,0	6	10	125	105	9/32"	5"	10
05007676001	1,6	9,0	8	13	150	112	11/32"	6"	10
05007677001	1,6	10,0	8	13	175	112	3/8"	7"	5

## 334 Slotted screwdriver



**Application:** Slotted screws

**Blade:** Round

**Design:** Chrome-plated, Lasertip


**Handle:** Kraftform with non-roll feature, multi-component, sizes 2.0 x 12.0, 2.5 x 14.0; Kraftform with non-roll feature, Weralit II, single-component

Code	mm	mm	mm	mm	mm	mm	mm	mm
05007610001	0,8	5,0	100	98	5,0	3/16"	4"	10
05007620001	1,0	6,0	125	105	6,0	1/4"	5"	10
05340330001	1,0	6,0	150	105	6,0	1/4"	6"	10
05110010001	1,2	6,5	150	105	6,0	1/4"	6"	10
05007635001	1,2	7,0	150	105	7,0	9/32"	6"	10
05007621001	1,2	6,5	200	105	7,0	9/32"	8"	5
05110011001	1,2	8,0	175	112	7,0	5/16"	7"	5
05007640001	1,6	8,0	175	112	7,0	5/16"	7"	5
05110104001	1,6	10,0	200	112	9,0	3/8"	8"	5
05110105001 <sup>1)</sup>	2,0	12,0	250	117	10,0	1/2"	10"	2
05018274001	2,5	14,0	250	117	16,0	9/16"	10"	2

1) without Lasertip



### How to prevent the screwdriver from slipping out of the screw head

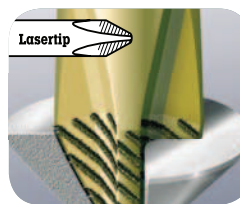

It happens time and time again that the tip slips out of the screw head when screwdriving, sometimes damaging valuable surfaces or even causing injury. The tips of the Wera Lasertip screwdrivers are microscopically roughened by means of a laser. This rough surface literally "bites" itself firmly into the screw head. Slipping out becomes a thing of the past.