



Brand of NTN corporation

Technical data

UCPG204

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC204G2, PG204

VISUAL (S)

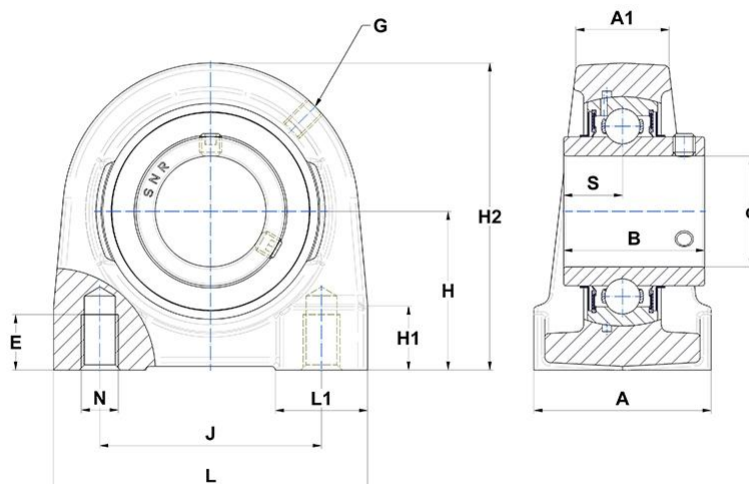

PRODUCT DEFINITION

Brand	SNR
A - Housing width	38 mm
A1 - Housing top width	20 mm
B - Width of Inner Ring	31 mm
d - Shaft diameter	20 mm
E - Mounting hole thread depth	16 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

G - Grease fitting	M6x1
H - Distance mounting base to centerline spheric. seating diam.	33,3 mm
H1 - Housing foot height	14 mm
H2 - Housing height	64 mm
J - Mounting holes distance	49 mm
L - Housing length	70 mm
L1 - Housing foot length	21 mm
N - Mounting hole dimension	M8
S - Distance front side/bearing centre	12,7 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	12800000 mN
C0 - Static load rating	6650000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,57 kg
Recommended tightening torque for set screw	5.5 N-m

