


Technical data

HK1516D

Drawn cup needle roller bearings, opened end

Needle roller bearing, drawn cup, open end

VISUAL (S)

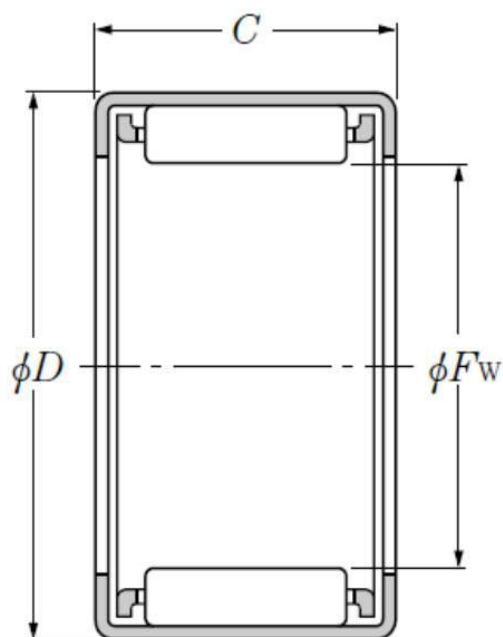

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	15 mm
D - External diameter	21 mm
C - Width of bearing, drawn cup or outer ring	16 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	2,5 mm
Inner ring reference	IR12X15X16.5
Mass	0,015 kg



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

HK1516D

Drawn cup needle roller bearings, opened end

PRODUCT PERFORMANCE

Cr - Dynamic load rating	10,7 kN
C0r - Static load rating	14,4 kN
N lim - Grease lubrication limit speed	11000 tr/min
N lim - Oil lubrication limit speed	16000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	HK1516D
Image	NRBHK_1.jpg, NRBHK_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15