

113A.CG - CHROMED SHEATH ADJUSTABLE WRENCHES | 113A.6CG




Norm :

NF ISO 6787, ISO 6787, DIN 3117, ASME B107.100

Description

- Good access to the button = easy setting.
- Non-protruding moving jaw at maximum capacity.
- Pre-adjustment of jaw opening thanks to millimetric gradation.
- Right-hand button rotation.
- Range from 4" to 12".
- Presentation: sheathed chromed body and polished head faces.

Information

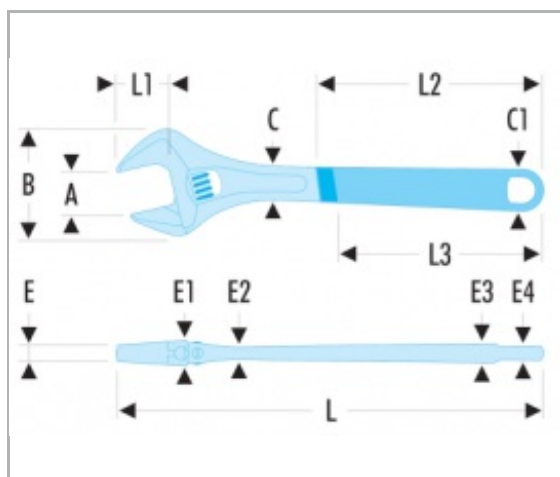

A [mm]	20
--------	----

B [mm]	45,0
--------	------

C1 [mm]	24,0
---------	------

E [mm]	5,0
--------	-----

E1 [mm]	11,8
---------	------

E2 [mm]	6,0
---------	-----

E3 [mm]	12,0
---------	------

E4 [mm]	8,0
---------	-----

L [mm]	159
--------	-----

L1 [mm]	19
---------	----

L2 [mm]	90,5
---------	------

[g]	140
-----	-----
