

Technical data sheet

BEKINA Thermolite

CONFIDENTIAL



BEKINA Thermolite


Size range	
● EU	39 - 47
● UK	6 - 12
● US	6 - 14
Weight / pair (43)	
● size 43	+/- 2.000 g

LEG

A. Dimensions	
● height	outer measure: 40 cm
● foot length	outer measure: 31,3 cm
	inner measure: 27,8 cm
● outline knee height	outer measure: 46,5 cm
● outline calf height	outer measure: 44 cm
● outline ankle	outer measure: 39,5 cm
B. Thickness	
● upper edge	4,5mm
● calf	7,6 - 8,4 mm
● shin-bone	6,1 - 9,0 mm
● ankle	11,7 mm
● heel	12,9 - 13,1 mm
● toe	10,7 mm
● instep	10,3 - 11,4 mm
C. Raw material	
	polyurethane
D. Colour	
	olivegreen
E. Environmental temperature	
● maximum	+/- 100°C
● minimum	-40°C (=thermo-insulating)

LINING

A. Material	
	PU coating on tricot
B. Seams	
	in front & middle of sole
	knitted or welded seams

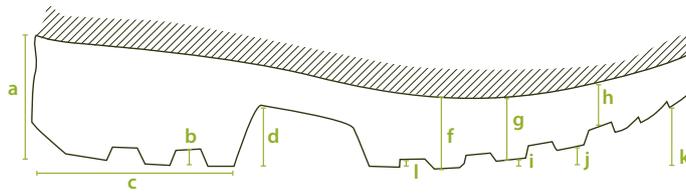

SOLE PROFILE

A. Dimensions	
● Heel	
• Thickness	(a) 55 mm
• Profile depth	(b) 10 mm
• Length	(c) 99 mm
• Width	(c) 99 mm
• Height until middle-foot support	(d) 17,5 mm
● Middle foot	
• Ladder anti-slip grips	(e) 1,8 mm
● Sole	
• Thickness	(f) 20,8 mm
	(g) 19,5 mm
	(h) 8,6 mm
• Profile depth	(i) 3 mm
	(j) 6 mm
	(k) 21 mm
	(l) 8,6 mm
B. Raw material	polyurethane
D. Color	black

DESIGN ASPECTS

● Lines on the boots	Elegant leisure time 'look'
● Sole	Few rolling to ensure all-over grip
	Enables you to 'walk' in it (bends along with foot)
● Sole profile	Light profile, conically built and with special anti-slip at toe-height
	Ladder anti-slip on intermediate foot (cambrure)
● Labeling	Through heat-transfer, ensures label remains stuck
	4-colour printing possible from 2.000 pairs
● Packaging	
• Quality label	Yes
• Packaging	4-coloured pairbox
• Quantity per carton	4 pairs of the same size