

FEATURES

- VDE proofed
- Rigid PVC, white RAL 9010
- Dimensions available:
 - 15 x 15 mm
 - 18 x 18 mm
 - 30 x 30 mm
 - 40 x 40 mm
 - 60 x 40 mm
 - 60 x 60 mm
 - 90 x 60 mm
 - 110 x 60 mm
- 2 m length
- Base including cover
- Hardly-inflammable, self-extinguishing
- Perforated bottom
- Ideal for new installation or renovation
- Designed for the use of dividers from size 60x60 mm onwards
- Two cable holders included from size 60x40 mm onwards
- External and internal corners and end caps available from size 40x40mm onwards

RS PRO VDE Installation Trunking



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Cable Trunking

Product Description

Product details:

- PVC installation trunking in white colour RAL 9010, with cover included
- For direct installation on wall and ceiling
- The material is hardly-inflammable and self-extinguishing
- The base with perforated bottom (distance 125 mm) allows an easy installation with screws
- Ideal for new installation or renovation
- The trunking is designed for the use of dividers from 60 x 60 mm onwards
- Two included cable holders per meter from 60 x 40 mm onwards for easy installation
- External corner parts, internal corner parts and end caps are available from size 40 x 40 mm onwards

General Specifications

Colour	White, RAL 9010
---------------	-----------------

Mechanical Specifications

Material	PVC (Polyvinylchlorid)
-----------------	-------------------------

Additional Information

EAN	
Custom Tariff Number	39259020

Classification

eCl@ss (Version)	
UNSPSC (Version)	

Approvals


Standards	VDE proofed and certificated according DIN EN 50085-1 and DIN EN 50085-2-1
RoHS compliant	yes

Similar Products


Stock No.	Product Name	Width	Height	Length / Piece	Packsize
2213612, 2213613	Installation Trunking	15 mm	15 mm	2000 mm	14 m
2213614, 2213615	Installation Trunking	18 mm	18 mm	2000 mm	16 m
2213616, 2213617	Installation Trunking	30 mm	30 mm	2000 mm	10 m
2213621, 2213622	Installation Trunking	40 mm	40 mm	2000 mm	8 m
2213623, 2213625	Installation Trunking	60 mm	40 mm	2000 mm	14 m
2213626, 2213627	Installation Trunking	60 mm	60 mm	2000 mm	8 m
2213628, 2213629	Installation Trunking	80 mm	60 mm	2000 mm	6 m
2213631, 2213632	Installation Trunking	110 mm	60 mm	2000 mm	4 m
Accessories					
2213619, 2213620	Divider	for use with trunking from 60 mm			10 m
	External Corner	for 40 x 40 mm trunking			1 piece
	Internal Corner	for 40 x 40 mm trunking			1 piece
	End Cap	for 40 x 40 mm trunking			1 piece
	External Corner	for 60 x 40 mm trunking			1 piece
	Internal Corner	for 60 x 40 mm trunking			1 piece
	End Cap	for 60 x 40 mm trunking			1 piece
	External Corner	for 60 x 60 mm trunking			1 piece
	Internal Corner	for 60 x 60 mm trunking			1 piece
	End Cap	for 60 x 60 mm trunking			1 piece
	External Corner	for 90 x 60 mm trunking			1 piece
	Internal Corner	for 90 x 60 mm trunking			1 piece
	End Cap	for 90 x 60 mm trunking			1 piece
	External Corner	for 110 x 60 mm trunking			1 piece
	Internal Corner	for 110 x 60 mm trunking			1 piece
	End Cap	for 110 x 60 mm trunking			1 piece

Accessories

External Corner

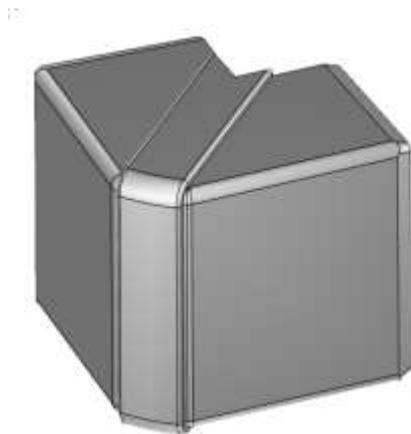

Internal Corner

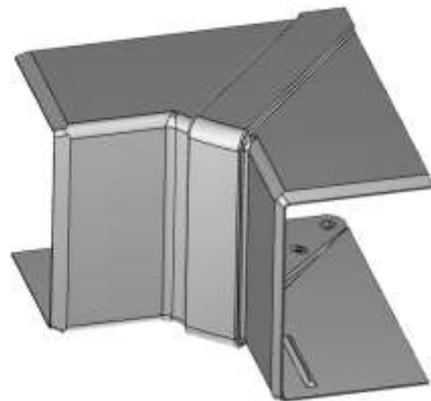

End Cap



Divider



