




Digital Precision Level
360°, with Data Output Pro 3600
Item number: 950-318

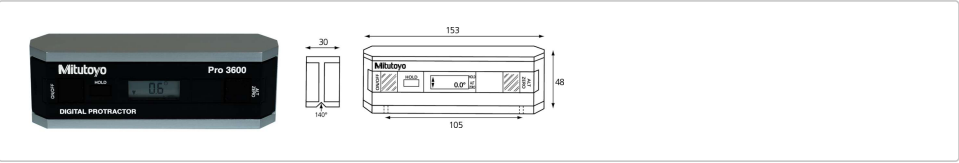

Description

- This Digital Precision Level offers you the following benefits:
- You can measure flatness, squareness and angularity.
 - Precision support surfaces in aluminium frame provide you with high rigidity and low weight.

Features

Max. permissible error (degrees):	0.05 (0 to 10) 0.1 (80 to 90) 0.2 (10 to 80)
Repeatability (degrees):	0.05
Data output:	Yes
Sensitivity (degrees):	0.01 (0 to 9.99) 0.1 (10 to 90)
Mass:	300 g
Range:	360° (4 x 90°)
Power supply:	Standard battery (9 V) 6LR61
Battery life:	ca. 500 hours
Delivered:	Including box

Accessories

Proposed additional products:



**RS-232C Output Cable
for series 950
50AAA983A**

Mitutoyo Digital Protractor Technical Specifications:

Order No	950-317	950-318
Model	Pro 360	Pro 3600
Accuracy	±0.1° Level ±10°, Plumb ±10°, ±0.2° Maximum error	0.05° (0° to 10°), 0.1° (80° to 90°), 0.2° (10° to 80°)
Battery Life	500 Hrs. Standard 9-Volt Battery	500 Hrs. Standard 9-Volt Battery
Cross Axis Error	Minimal	Minimal
Output	N/A	RS-232C Compatible
Repeatability	±0.1°	±0.05°
Resolution	0.1°	0.01° (0° to 9.99°), 0.1° (10° to 90°)
Storage Temperature	-20-65°C -4-149°F	-20-65°C -4-149°F
Weight	289g 10.2oz	295g 10.4oz
Operating Temperature	-5-50°C 23-122°F	-5-50°C 23-122°F