


solenoid coil MSFG-12-OD

Part number: 34410

FESTO

For DC voltage, without plug socket.

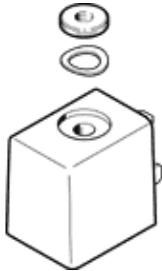

Data sheet

Feature	Value
Assembly position	Any
Switching position indicator	No
Min. pickup time	10 ms
Duty cycle	100 %
Characteristic coil data	12 V DC: 4.1 W
Permissible voltage fluctuation	+/- 10 %
Protection class	IP65
Ambient temperature	-5 ... 40 °C
Max. tightening torque, plug socket	0.4 Nm
Product weight	55 g
Electrical connection	Plug vanes for MSSD-F 3-pin
Mounting type	With knurled nut
Materials note	Conforms to RoHS
Material solenoid coil	Duroplast Copper Steel
Material winding	Copper