

Item code

TCHI 10



Brief description:

bulkhead mounting housings with 2 levers, size "57.27", thermoplastic version, IP65

Product description

Version	T-TYPE insulating enclosures
Series	Bulkhead mounting housings with 2 levers
Product type	with two levers in thermoplastic material
Family	T-TYPE insulating enclosures
Size	size "57.27"

Technical data

Operating temperature range (min, max)	-40°C ... +90°C
Material	thermoplastic
IP degree of protection	IP65

Other technical details

Weight	81,00 g
---------------	---------

Approvals / Standards

Quality mark	 (type:12), EAC
Conformity	CQC, CE

General ordering information

EAN code	8015747168540
Tariff number	85369095

Packaging Information


Packaging length	305,00 mm
Packaging height	180,00 mm
Packaging width	275,00 mm
Packaging weight	3,22 kg
Packaging volume	15,10 dm ³
Packaging description	Carton box
Packaging quantity	40 Pcs
Packaging EAN code	8015747170147
Sub-packaging weight	0,40 kg
Sub-packaging description	Plastic pakaging
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747170154

Item code

TCHI 10



Catalogue drawings

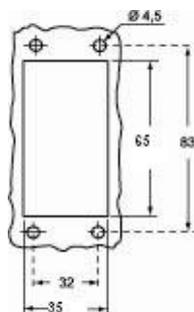

Catalogue drawings

