




Pro Fit® Ergo TB450 Trackball

Whether you're working from home, the office or on-the-go, today's users seek device solutions that prioritise both comfort and productivity, whilst keeping sustainability at the forefront.

The Pro Fit® Ergo TB450 Trackball allows users to effortlessly transition from a mouse to a trackball and unlock the ergonomic advantages and space-saving benefits it offers. With its thoughtful design, the TB450 utilises 50% recycled material, reducing the use of new plastics.

Bluetooth® Low Energy or 2.4GHz wireless connectivity offer maximum flexibility. The TB450 also features a long battery life, a patented ball ejection system that simplifies cleaning and precise optical tracking.

Elevate your work setup with the Pro Fit® Ergo TB450 Trackball - where comfort, productivity and sustainability converge.

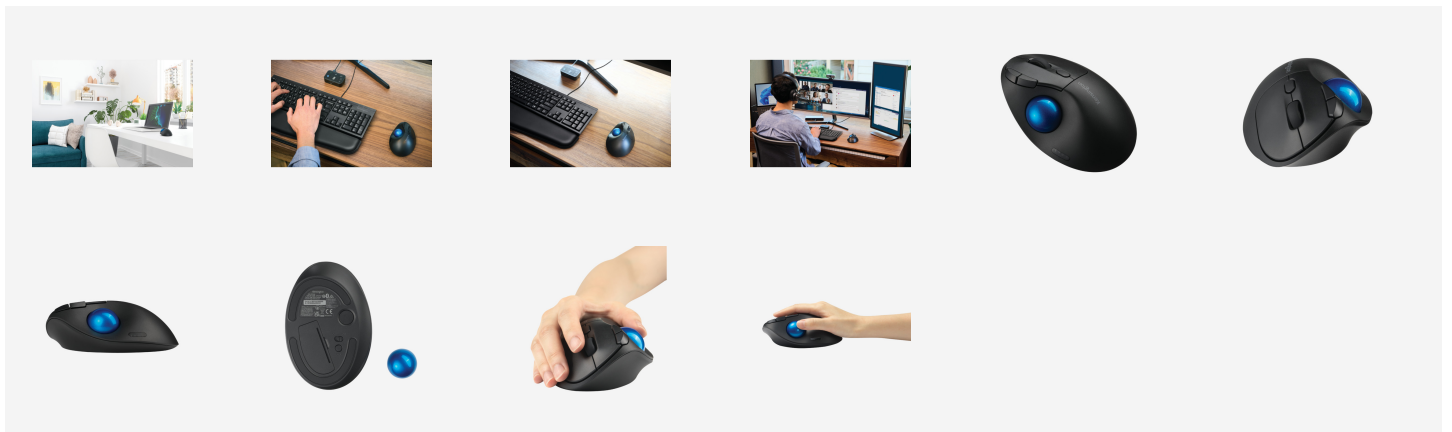

Attributes

- The sculpted ergonomic design provides all-day comfort and features a unique 45° tilt that helps improve wrist and forearm alignment.
- 50% of overall plastic is recycled plastic - Kensington is committed to help reduce the impact of plastic on the global environment.
- Choice of Bluetooth® Low Energy (LE) and 2.4GHz wireless connection options (2.4GHz nano receiver included).
- Long battery life - up to 18 months (2.4GHz) and or 15 months (Bluetooth®).
- A patented ball ejection system features a unique, easy-to-clean design with built-in trackball ejection button to effortlessly remove the trackball for cleaning when needed.
- A high-quality optical sensor accurately tracks the 34mm thumb-operated trackball, giving users smooth cursor control and optimal precision. The TB450 offers 4 switchable cursor speeds (400, 800, 1200 and 1600DPI).
- Plug & Play Installation for simple setup. Free KensingtonWorks™ software allows the TB450 to be personalised to enhance productivity.
- Government-grade 128-bit AES encryption for enhanced security to deter hackers from monitoring wireless connection and capturing sensitive information.

Specifications

Number	K72194WW
Colour	-----
Dimensions (W x H x D)	93 x 50 x 138 mm
Weight	200 g
Pallet quantity	336
EAN code	85896721949