

T 11/1 CLASSIC DRY VACUUM CLEANER

Lightweight, high suction power, very robust: our T 11/1 Classic dry vacuum cleaner combines the key criteria sought by professional users in an attractively priced, compact vacuum cleaner.



Order no. **1.527-198.0**

- 11-l container, lightweight, quiet, robust, good price-performance ratio
- Good track properties, all-round bumper, cable hook
- Floor nozzle 270 mm, classic bend/suction hose, stainless steel suction tube, filter basket

Technical data

EAN code		4054278731124
Number of current phases	Ph	1
Voltage	V	220 - 240
Frequency	Hz	50 - 60
Vacuum	mbar / kPa	235 / 23.5
Air flow	l/s	40
Nominal power	W	850
Container capacity	l	11
Standard nominal width		ID 35
Cable length	m	7.5
Sound pressure level	dB(A)	61
Colour		anthracite
Weight without accessories	kg	3.9
Weight incl. packaging	kg	6.2
Dimensions (L × W × H)	mm	385 × 285 × 385

Scope of supply

Suction hose length:	2 m
Bend:	Plastic
Quantity of suction tubes:	2 Piece(s)
Suction tubes length:	480 mm
Suction tubes material:	Stainless steel
Switchable floor nozzle	
Quantity of filter bags:	1 Piece(s)
Filter bag material:	Fleece
Motor protection filters	
Permanent filter basket:	Fleece

Equipment

Container material:	Plastic
Cable hook	
Integrated accessory storage	



Low weight

- Effortless, also one-handed transport over ledges and steps.
- Lower weight with identical container volume compared to competitor models.
- Designed for long periods of fatigue-free use.



Very low operating noise of only 61 dB(A)

- Ideal for working in noise-sensitive areas and at night.
- Low operating noise protects the user.



Cable hook

- The power cable is always stored safely for transport.
- Practical cable storage.

EQUIPMENT FOR T 11/1 CLASSIC DRY VACUUM CLEANER


1.527-198.0



		Order no.	Description	
FILTER T/ NT				
Main filter baskets				
Permanent main filter basket, T 7/1, T 8/1, T 11/1, ProT 200	1	2.889-099.0	Robust and durable: permanent main filter basket made of non-woven material. The sustainable filter basket can be washed by hand at 30 °C and reused. Content: 1 piece.	■
Exhaust air filter				
Motor protection filter, 1 Piece(s), T 9/1 Bp, T 7, T 8, T 10, T 11, T 12, T 15	2	6.414-022.0	Motor protection filter, removable fleece, which can be replaced when heavily soiled.	■
HEPA filter for dust class H				
Set HEPA T 11/1	3	2.889-310.0	HEPA 14 filter set, comprising highly effective HEPA 14 filter, as well as the compatible main filter basket.	□
Fabric filter bag				
Filter bag cloth	4	6.904-316.0	The fabric filter bag for Kärcher dry vacuum cleaners is made of cotton and can be washed at up to 40 °C.	□
BENDS				
Plastic bend				
Elbow packaged NW35	5	2.840-040.0	DN 35 plastic bend for Classic dry vacuum cleaners. Comes with a Clip Classic connection at the hose end and a cone connection at the accessory end.	■
SUCTION NOZZLES				
All-purpose nozzles (wet/dry)				
Combi-nozzle	6	6.907-496.0	Switchable floor nozzle for cleaning textile and hard surfaces. Made of plastic with a width of 270 mm and nominal size of DN 35. Includes practical parking hook.	■
Floor tool packaged	7	2.889-360.0	High-quality plastic floor nozzle in nominal size of DN 35 for cleaning textile and hard floors. With a practical parking hook. Width: 290 mm.	□
Suction brushes				
Suction brush packaged NW 35	8	2.889-221.0	Suction brush DN 35 with horsehair natural bristles.	□
Turbo nozzle				
Floor tool TURBO DN 35/32	9	2.860-277.0	Plastic turbo floor nozzle in nominal size of DN 35/32 for cleaning textile and hard floors. With a practical parking hook and DN 35/32 reduction bushing, 270 mm wide.	□
SUCTION HOSES				
Suction hoses others				
Complete suction hose replacement	10	2.889-100.0	The suction hose in nominal width DN 35 and with 2 m length is suitable for use with Classic dry vacuum cleaners.	■
VACUUMS				
Nozzles				
Flexible Crevice Nozzle	11	2.863-374.0	Flexible crevice nozzle for cleaning hard-to-reach areas in the home, basement, workshop, car, etc. with Home & Garden wet and dry vacuum cleaners and spray extraction cleaners.	□
NOZZLE SETS				
Nozzle kit: crevice nozzle, upholstery nozzle, suction brush, ID 35	12	2.860-116.0	Nozzle kit consisting of a crevice nozzle, upholstery nozzle and suction brush. The nozzle kit is suitable for all Kärcher dry vacuum cleaners and wet and dry vacuum cleaners in nominal width DN 35.	□
FURTHER ACCESSORIES DRY VACUUM CLEANERS				
Repair set Kaercher NW35	13	2.639-329.0	Repair kit for dry vacuum cleaner accessories in DN 35. The kit includes a threaded and clamping ring, a connecting adapter, as well as a seal.	□
Set hand nozzle	14	2.889-361.0	Innovative surface nozzle with nominal width DN 35 for dry vacuum cleaners from Kärcher. The nozzle can be used on both hard and carpeted surfaces. Working width: 180 mm.	□

■ Included in delivery. □ Available accessories.

EQUIPMENT FOR T 11/1 CLASSIC DRY VACUUM CLEANER
1.527-198.0

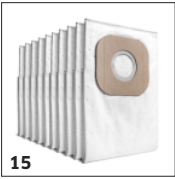

		Order no.	Description	
FILTER BAGS				
Fleece filter bags (3 ply)				
Fleece filter bags, 10 Piece(s), T 7/1 Classic, T 8/1, T 11/1 Classic	15	6.904-084.0	Tear-resistant 3-layer fleece filter bags of dust class M, suitable for Kärcher dry vacuum cleaners. Contents: 10-pack.	☐

☐ Available accessories.