



Application Tooling > Portable Crimp Tools



Tool Grade: **Commercial Crimp Tooling**
Ratchet Configuration: **Operator Releasable & Adjustable**
Die Sets Type: **Removable/Interchangeable**
Specification Type: **TE Product Specification (114-)**
TE Certification: **Upon Request for Fee**

Features

Other

Crimp Form-Wire Barrel Type	Open Barrel - F Crimp
Tool Grade	Commercial Crimp Tooling
Ratchet Configuration	Operator Releasable & Adjustable
Die Sets Type	Removable/Interchangeable
Specification Type	TE Product Specification (114-)
TE Certification	Upon Request for Fee
Power Technology Type	Battery, Electric, Manual
Tooling Type	PRO-CRIMPER Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2022 (223) Candidate List Declared Against: JAN 2021 (211) SVHC > Threshold: Not Yet Reviewed

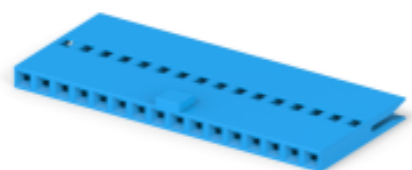
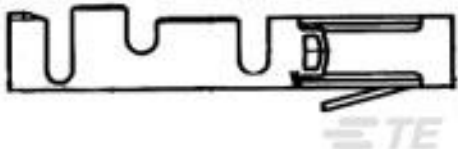
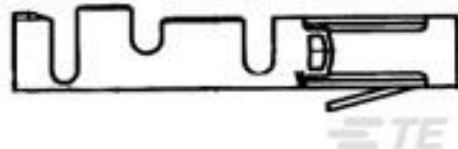
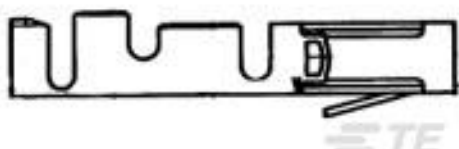
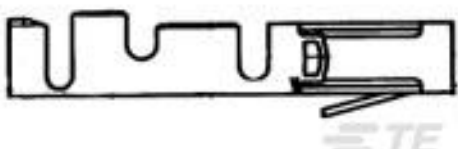
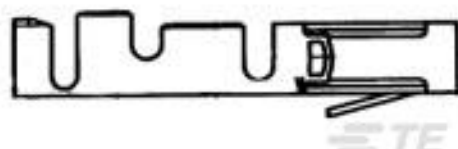
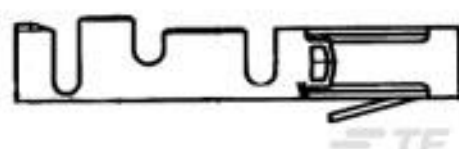
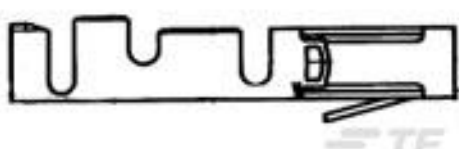
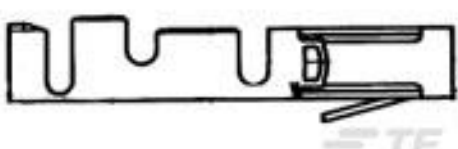


Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

 TE Part # CAT-F439-S01339254 2.54mm FFC Connectors Socket Contacts	 TE Part # CAT-F439-P65254 2.54mm FFC Connectors Pin Contacts	 TE Part # 181270-1 AMP-MODU CONTACT	 TE Part # 181270-2 MOD II CONTACT L.P.
 TE Part # 181270-3 MOD 2 BUCHSE	 TE Part # 280530-4 MOD2 BUCHSE	 TE Part # 280530-2 AMP MODU MOD 2 CONT	 TE Part # 280530-1 MOD II COSI RECP CONT STR PH-B
 TE Part # 280530-3 MOD II COSI RECP CONT STR PRE	 TE Part # 1-280530-1 MOD II COSI RECP CONT STR PH-B	 TE Part # 182206-2 MOD 2 TERMINAL	 TE Part # 181270-4 MOD 2 BUCHSE




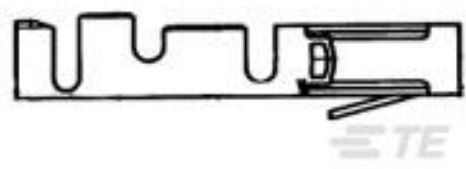


TE Part # 1-280530-2
MODU 2 F BDE

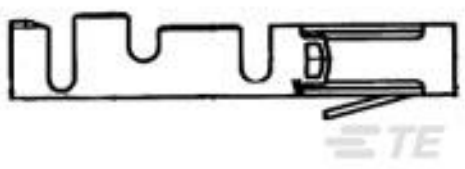

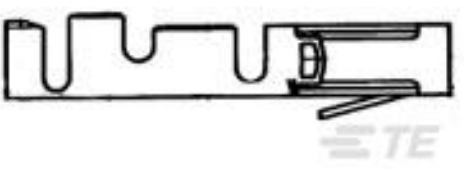
TE Part # 1-280530-3
MOD 2 RECPT SNAP IN RIG TO LEF



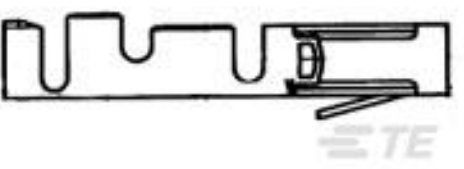TE Part # 1-280530-4
MOD 2 RECPT RIGHT TO LEFT



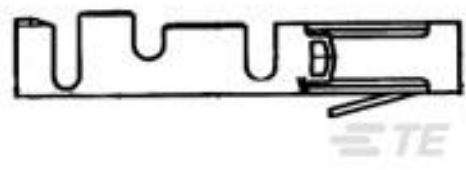TE Part # 280530-5
MOD II CONT RECEPT SNAP ON



TE Part # 280530-6
MOD II COSI RECP CONT STR

Customers Also Bought



TE Part #1658544-2
PIN CONT DUPL PLT STRIP HD-20



TE Part #86566-4
FFC RECP CRIMP S-I



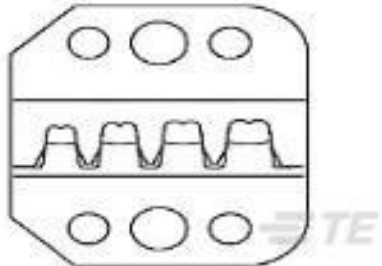
TE Part #280359
AMPMODU II REC. HSG, SINGLE ROW, 4 POS.



TE Part #58654-1
PRO-CRIMP TL & DIE MOD II



TE Part #5053154018
RNF-100-3/8-2-SP



TE Part #58535-2
PRO-CRIMPER ASSY MODU



TE Part #1-1393763-4
V23100V4024A



TE Part #8862813001
FLHTC0311-26-2



TE Part #9037513001
FLHTC0311-26-6

Documents



Datasheets & Catalog Pages

1-1773865-2_1015_Commercial Manual Hand Tools

English

Bottoming Dies

English

Instruction Sheets

Instruction Sheet (U.S.)

English