

Datasheet

ENGLISH


RS PRO DC Motor, 5.75 W, 6 - 15 V dc, 64.2 gcm, 8768 rpm, 2.31mm Shaft Diameter

Stock No: 238-9715



Specifications:

Supply Voltage	6 - 15V
Power Rating	5.75 W
Output Speed	8768 rpm
Shaft Diameter	2.31mm
Maximum Output Torque	64.2 gcm
Length	32.5mm
Dimensions	27.63 (Dia.) x 32.5mm
Current Rating	758 mA
Weight	51g

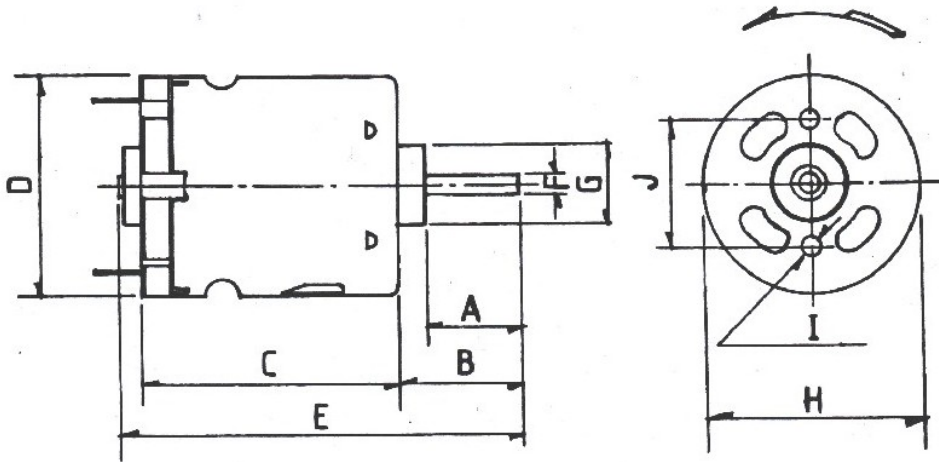

Dimensions	A	B	C	D	E	F	G	H	I	J
mm	8.2	11.5	32.5	27.63	47	2.305	10	27.5	M2.6	16

Stall Current RE-360 at 12v = 4.02A