

P2RV-A□□□C


Cable, single sided 10 pole IDC connector, to connect to P2RVC-8-O-F

List of Models

Model number	Cable length
P2RV-A100C	1.0 m
P2RV-A200C	2.0 m
P2RV-A300C	3.0 m
P2RV-A500C	5.0 m

10 pole IDC mounting to P2RVC-8-O-F

10	→	←	WHITE	Open end
9	→	←	GREY	
8	→	←	PURPLE	
7	→	←	BLUE	
6	→	←	GREEN	
5	→	←	YELLOW	
4	→	←	ORANGE	
3	→	←	RED	
2	→	←	BROWN	
1	→	←	BLACK	

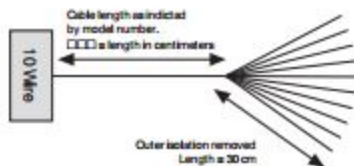

Technical data

Control line	AWG26/0.14 mm ² , tin-plated copper
Diameter cable	6.8 mm
Operating voltage	60 VDC
Continuous current per signal wire	0.5 A
Max. total current	1.0 A
Test voltage	0.5 KV, 50 Hz, 1 min
Operating temperature range	-20°C to +50°C