



Figure similar

SETRON, cylindrical fuse link, Class CC, 8 A, time-lag, Un AC: 600 V, respect national installation rules! for protection of control transformers, reactors and selenoids


Model			
product brand name		SETRON	
product designation		Cylindrical fuse link	
General technical data			
operating class of the fuse link		Slow	
type of voltage of the operating voltage		AC	
Main circuit			
operational current rated value		8 A	
Product details			
product component striker		No	
Mechanical Design			
mounting position		Any, preferably vertical	
net weight		9 g	
Approvals Certificates			
General Product Approval		other	Environment



[Confirmation](#)

[Environmental Confirmations](#)

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW1080-0HG
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/3NW1080-0HG
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW1080-0HG
CAX-Online-Generator http://www.siemens.com/cax
Tender specifications http://www.siemens.com/specifications

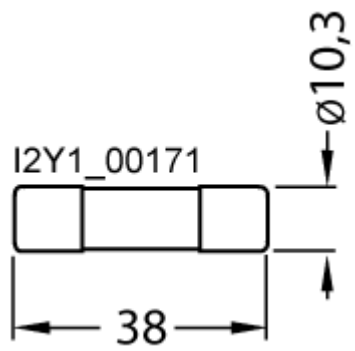

last modified:

5/26/2025 

