


CARACTERÍSTICAS

- Ideal para trabajo de precisión con cable blando
- Mordazas de acero de 3 mm con conexión a tierra y precisión
- Sujeciones de plástico suaves acanaladas y muelle de retorno ligero
- El tope integral impide que las asas se abran demasiado

Alicates RS Pro de punta plana de acero 140mm con 30mm mordaza Longitud

Código RS 606-529

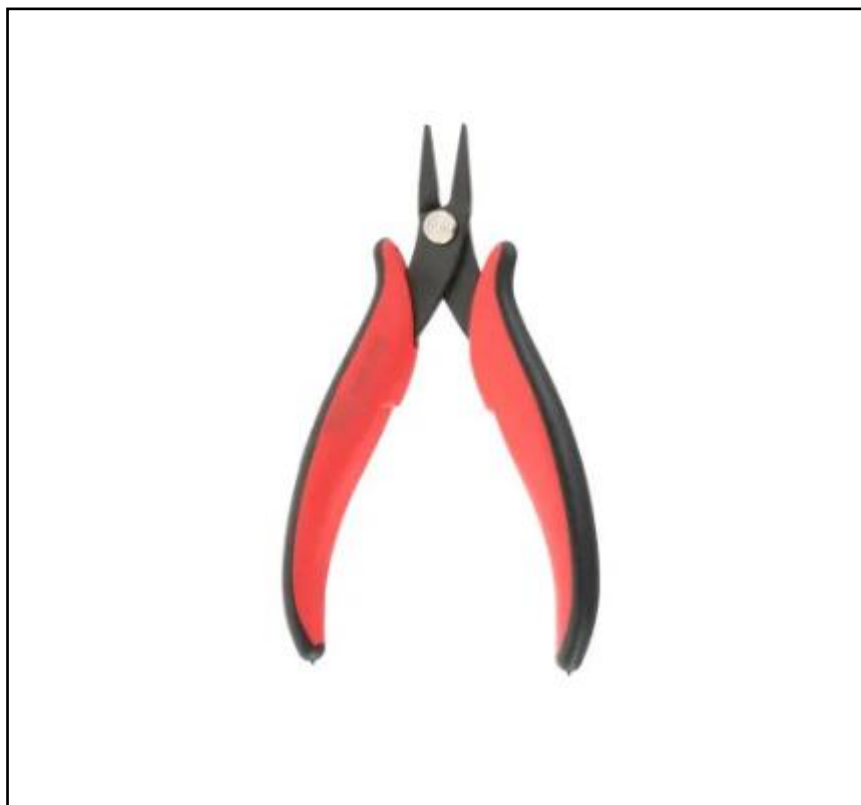

Los productos con aprobación profesional RS le proporcionan piezas de calidad profesional en todas las categorías de productos. Nuestra gama de productos ha sido probada por ingenieros y proporciona una calidad comparable a las marcas líderes sin pagar un precio superior.

Descripción del

RS Pro presenta estos alicates de punta larga de alta calidad adecuados para profesionales y aficionados. Con bordes externos redondeados, estos alicates de punta suave son adecuados para la manipulación de componentes en áreas de alta densidad sin causar daños.

Especificaciones

Tipo alicates	Alicates de punta plana
Estilo de punta	Recta
Material	Acero
Aplicaciones	Trabajo eléctrico, joyería

Especificaciones mecánicas

Capacidad de corte	3 mm
Longitud de mordaza	30mm
Longitud total	140mm
Peso	78g



<p>All dimensions are in mm</p>	<p>FLAT NOSE PLIER</p>	<p>P10</p> <ul style="list-style-type: none"> ● Precision nose plier with serrated jaws ● Jaw width 3mm ● Length 140mm
<p>All dimensions are in mm</p>	<p>LONG NEEDLE NOSE PLIER</p>	<p>P11</p> <ul style="list-style-type: none"> ● Long-needle nose plier with serrated jaws ● Tapered jaw to 1.2mm width ● Length 152mm
<p>All dimensions are in mm</p>	<p>FLUSH CUTTER</p>	<p>P13</p> <ul style="list-style-type: none"> ● Max wire ϕ 16 AWG/.051" (1.3mm) soft wire ● Cutting angle 21° ● Length 132mm ● Safety clip available. Add "-A" to Part No.
<p>All dimensions are in mm</p>	<p>LIGHTWEIGHT FLUSH CUTTER</p>	<p>P13-LW</p> <ul style="list-style-type: none"> ● Max wire ϕ 16 AWG/.051" (1.3mm) soft wire ● Cutting angle 21° ● Lightweight 1.6oz (45g) ● Length 125mm ● Safety clip available. Add "-A" to Part No.
<p>All dimensions are in mm</p>	<p>ANGLED FLUSH CUTTER</p>	<p>P14</p> <ul style="list-style-type: none"> ● Max wire ϕ 16 AWG/.051" (1.3mm) soft wire ● Cutting angle 21° ● Length 130mm ● Safety clip available. Add "-A" to Part No.
<p>All dimensions are in mm</p>	<p>FLUSH CUTTER</p>	<p>P15</p> <ul style="list-style-type: none"> ● Max wire ϕ 16AWG/.051" (1.3mm) ● Cutting angle 48° ● Length 130mm
<p>All dimensions are in mm</p>	<p>ANGLED HEAD CUTTER</p>	<p>P17</p> <ul style="list-style-type: none"> ● Max wire ϕ 18 AWG/.040" (1.0mm) ● Cutting angle 30° ● Length 140mm
<p>All dimensions are in mm</p>	<p>WIRE STRIPPER</p>	<p>P21</p> <ul style="list-style-type: none"> ● Max wire ϕ 28-24 AWG/.012"-.020" (0.3-0.5mm) ● Length 132mm
<p>All dimensions are in mm</p>	<p>LONG FLAT NOSE PLIER</p>	<p>P24</p> <ul style="list-style-type: none"> ● Long flat nose plier with serrated jaws. ● Jaw width 3mm ● Length 152mm