


Intermediate-position module DADM-DGC-40-A

Part number: 541702

FESTO

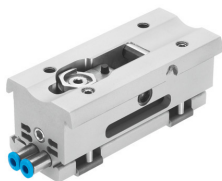

 [General operating condition](#)

Data sheet

Feature	Value
Size	40
Mounting position	optional
Position detection	Via proximity switch
Operating pressure	0.25 MPa ... 0.8 MPa
Operating pressure	2.5 bar ... 8 bar
Operating pressure	36.25 psi ... 116 psi
Max. impact speed	3 m/s
Max. swivel time	300 ms
Repetition accuracy	0.02 mm
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	970 g
Type of mounting	Clamped to cylinder DGC
Pneumatic connection	M5
Note on materials	RoHS-compliant
Material stop screw	Steel Galvanised
Material seals	TPE-U(PU)
Material housing	Wrought aluminium alloy Anodised
Material lever	High-alloy stainless steel
Material clip	High-alloy stainless steel
Material nut	Steel Galvanised
Fine adjustment	4 mm
Mode of operation	Double-acting