

# HC-D 25-AP-GY - Cover plate

1660355

<https://www.phoenixcontact.com/in/products/1660355>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

HEAVYCON cover plate, for wall cutouts of type D25, 3.5 mm thick, gray



## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 1660355                        |
| Packing unit                         | 10 pc                          |
| Minimum order quantity               | 10 pc                          |
| Note                                 | Made to order (non-returnable) |
| Sales key                            | BF7                            |
| Product key                          | AF7AZD                         |
| Catalog page                         | Page 664 (C-2-2019)            |
| GTIN                                 | 4017918021993                  |
| Weight per piece (including packing) | 14.69 g                        |
| Weight per piece (excluding packing) | 14.69 g                        |
| Customs tariff number                | 39269097                       |
| Country of origin                    | DE                             |

# HC-D 25-AP-GY - Cover plate

1660355

<https://www.phoenixcontact.com/in/products/1660355>



## Technical data


### Notes

|         |                              |
|---------|------------------------------|
| General | For wall cutouts of type D25 |
|---------|------------------------------|

### Product properties

|              |             |
|--------------|-------------|
| Product type | Cover plate |
| Type         | D25         |
| Seal present | yes         |

### Dimensions
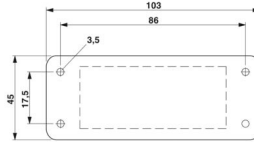
|                                 |                                                                                    |
|---------------------------------|------------------------------------------------------------------------------------|
| Dimensional drawing             |  |
| Width                           | 45 mm                                                                              |
| Height                          | 3.5 mm                                                                             |
| Length                          | 103 mm                                                                             |
| Drill hole distance, horizontal | 86 mm                                                                              |
| Drill hole distance, vertical   | 17.5 mm                                                                            |
| Hole diameter                   | 3.5 mm                                                                             |

### Installation dimensions

|                               |       |
|-------------------------------|-------|
| Width of the assembly cutout  | 24 mm |
| Length of the assembly cutout | 74 mm |

### Material specifications

|                                        |     |
|----------------------------------------|-----|
| Material                               | PA  |
| Flammability rating according to UL 94 | HB  |
| Seal material                          | PTS |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection            | IP54              |
| Ambient temperature (operation) | -20 °C ... 100 °C |


# HC-D 25-AP-GY - Cover plate

1660355

<https://www.phoenixcontact.com/in/products/1660355>



## Drawings

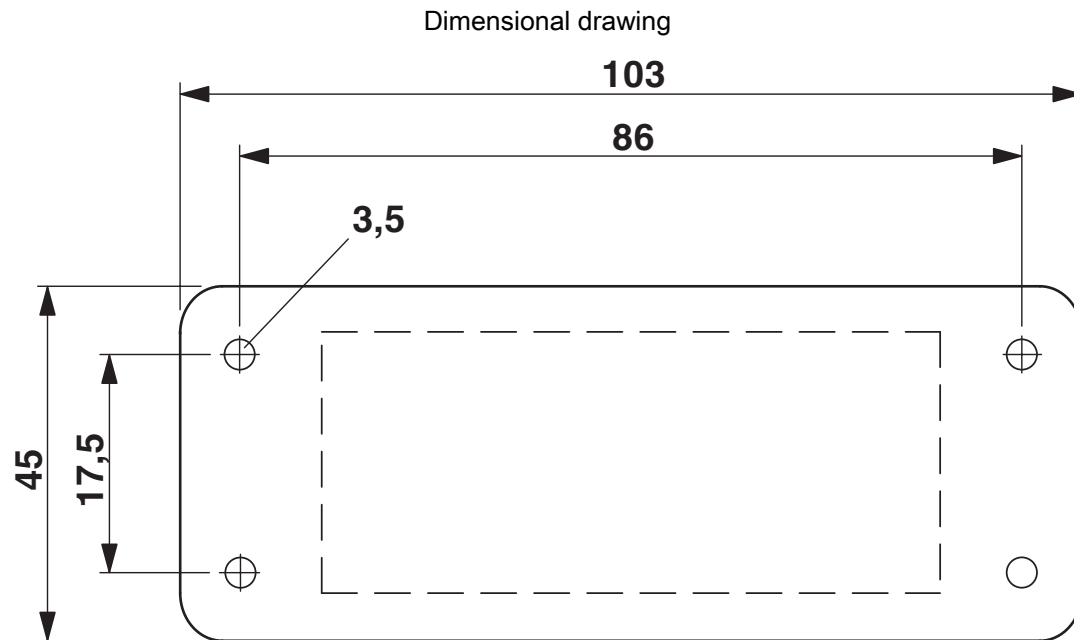

Dimensional drawing

# HC-D 25-AP-GY - Cover plate

1660355

<https://www.phoenixcontact.com/in/products/1660355>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27440201 |
| ECLASS-12.0 | 27440201 |
| ECLASS-13.0 | 27440201 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002309 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-D 25-AP-GY - Cover plate

1660355

<https://www.phoenixcontact.com/in/products/1660355>



## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.  
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420  
[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)