





Technical data

51308

One direction thrust ball bearings

VISUAL (S)

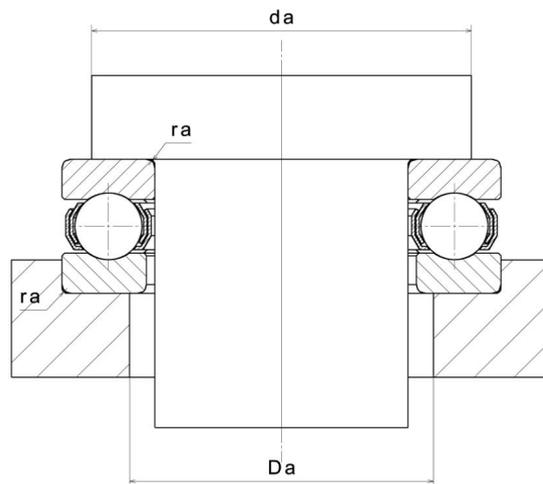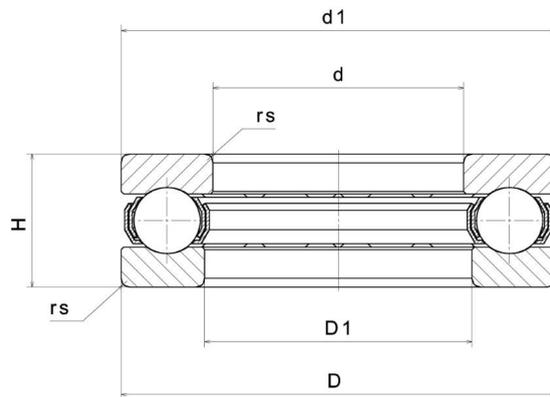

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	40 mm
D - External diameter	78 mm
T - Thrust bearing height	26 mm
rs - Min fillet radius	1 mm
Mass	0,548 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	69000000 mN
C0a - Static axial load rating	135000000 mN
Cua - Limit axial load rating	6050000 mN
N lim - Oil lubrication limit speed	18600 °/s
N lim - Grease lubrication limit speed	13200 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	55 mm
da min - Min shoulder diameter IR	63 mm

