


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

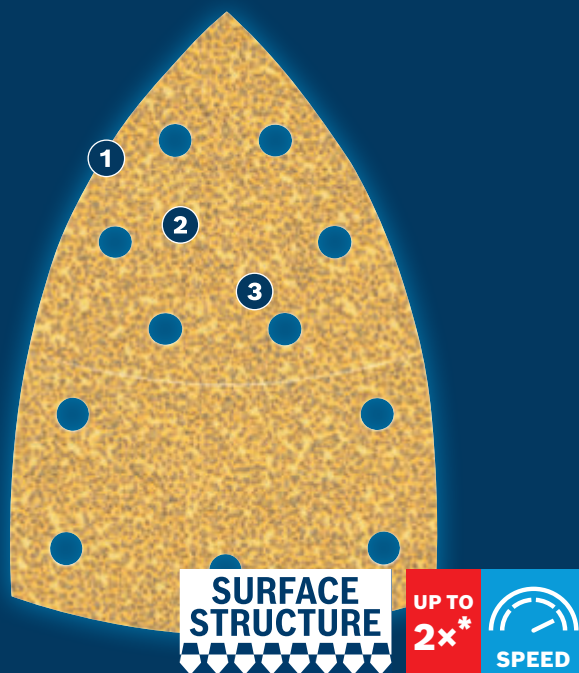


* vs. Bosch C420



BOSCH

EXPERT C470 SANDPAPER

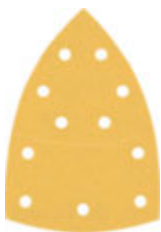

- ▶ Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 2x faster than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop



PRODUCT PROPERTIES				ORDERING INFORMATION				
Sheet dimensions mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number	
102x62	4x60 4x120 4x120	11 holes	C1a	10	5	638 249	2 608 901 676	
102x62	40	11 holes	C1a	10	5	542 249	2 608 900 886	
102x62	60	11 holes	C1a	10	5	636 023	2 608 901 652	
102x62	80	11 holes	C1a	10	5	542 256	2 608 900 887	
102x62	120	11 holes	C1a	10	1	542 263	2 608 900 888	
102x62	180	11 holes	C1a	10	5	542 270	2 608 900 889	
102x62	240	11 holes	C1a	10	5	636 030	2 608 901 653	
102x62	40	11 holes	C0a	50	1	635 965	2 608 901 646	
102x62	60	11 holes	C0a	50	1	635 972	2 608 901 647	
102x62	80	11 holes	C0a	50	1	635 989	2 608 901 648	
102x62	120	11 holes	C0a	50	1	635 996	2 608 901 649	
102x62	180	11 holes	C0a	50	1	636 009	2 608 901 650	
102x62	240	11 holes	C0a	50	1	636 016	2 608 901 651	



BOSCH