



fitted with

- work equipment
- connected load
- power consumption
- system of protection
- class of protection
- technology
- usage
- luminaire body
- lamp cover
- tubular sections
- balance of articulation joints
- weight (net)
- mains lead

fastening

special features

- 3 x Light-emitting diode
- light colour daylight white, 5500-6000 K, Color Rendering Index (CRI)=72
- Energy efficiency category A+
- electronic plug-in transformer
- 100-240 V; 50/60 Hz
- approx. 7 W
- IP 20 (65)
- II
- switchable
- switch
- aluminium, anodised, black
- glass screen
- flexible metal tube, Jet black
- friction
- approx. 1.6 kg
- approx. 2.7 m; mains plug
- BS 1363
- CEE 7/XVI
- NEMA 1-15P
- screw-down flange, magnetic base (accessory), table clamp (accessory), wall bracket (accessory)
- Spot with a 10° angle of radiation



BS 1363



CEE 7/XVI




NEMA 1-15P

illuminance

measuring conditions: d=50cm

Em: 4068 lx
Emax: 27500 lx
Emin: 400 lx

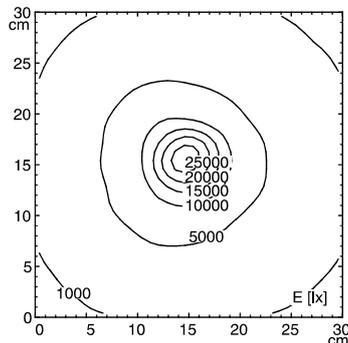

luminous intensity

