


Manifold sub-base VABX-A-ER-E12-JHTH-XR

Part number: 8191781

FESTO

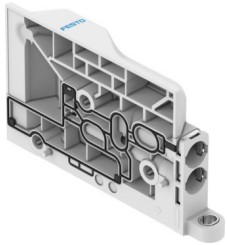

 [General operating condition](#)

Data sheet

Feature	Value
Integrated function	Pilot air selector for defining the pilot air supply (internal or external)
Flow direction	Reversible
Compatible with	Valve terminal VTUX-A-P Valve terminal VTUX-A-S
Suitability for vacuum	yes
Dimensions (W x L x H)	15.05 mm x 104.3 mm x 66.55 mm
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C ... 70 °C
Ambient temperature	-5 °C ... 50 °C
Max. tightening torque wall mounting	6 Nm
Product weight	57.9 g
Mounting method for sub-base	With through-hole
Pilot air port 12/14	For 12 mm cartridge
Pilot exhaust port 82/84	For 12 mm cartridge
Note on materials	RoHS-compliant
Material seals	NBR
Material housing	PA-reinforced
Material sleeve	High-alloy stainless steel
Material clip	High-alloy stainless steel