

Illumination element

Distribution by
Rs-online

45-320.2G16

<https://rs-online.eao.com/p/45-320.2G16>

Your product:



45-320.2G16

Illumination element

MOUNTING

Component mounting type: Base mounting

OPERATING-/INDICATION PART

Illumination colour: Yellow

ELECTRICAL CHARACTERISTICS

Operating voltage: 24 V AC/DC

Surge voltage resistance: 4 kV

Lumi. Intensity: 900 - 1400 mcd

MECHANICAL CHARACTERISTIC

Terminal: Screw terminal

Weight: 0.02 kg

CERTIFICATE

REACH: REACH compliant


RoHS: RoHS compliant

OTHER

Short Description: Illumination element, Screw terminal, Yellow, 24 V AC/DC, Base mounting

Hints: Illumination element base mounting can used only with enclosure

Wiring diagrams:

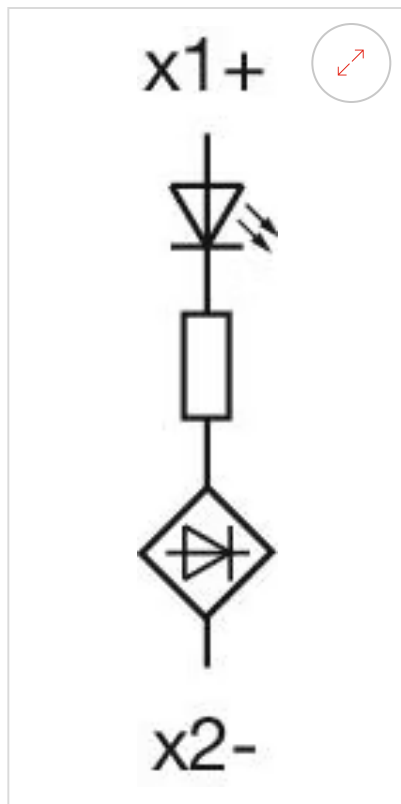

Dimension drawings:

