




Sample photo

**Order symbol:** CAB P 806030  
**Product nbr:** 8104308  
**Description:** Polyester cabinet  
**Remarks:** Grey door

**EAN:** 6418074050052  
**El. number:**  
 Finland 3424143  
 Denmark 8212018057  
 Sweden 2539827

**Including:** Cabinet base, door with PUR gasket, 3mm double bit lock(s) with transport and plastic key, screws for mounting plate/DIN-rail and wall fastening lugs with screws. Wall mounting screws not supplied.

Dimensions:			Rating:	
	L	W	H	
mm:	800	600	300	<b>Ingress Protection (EN 60529):</b> IP 66
inch:	31.5	23.6	11.8	<b>Impact Resistance (EN 50102):</b> IK 10
Materials:			<b>Electrical insulation:</b> Totally insulated	
<b>Material:</b>	GRP		<b>UV resistance:</b> UL 508	
<b>Base colour:</b>	RAL 7032		<b>Flammability Rating (UL 746 C 5):</b> UL 94 5V	
<b>Cover colour:</b>	RAL 7032		<b>Glow Wire Test (IEC 695-2-1) °C:</b> 960	
<b>Cover screws material:</b>	Stainless steel		<b>UL Type:</b> UL TYPE 3, 3R, 3S, 4, 4X, 12, 13	
<b>Gasket material:</b>	Polyurethane		Certificates:	
Temperatures:				
<b>Short term:</b>	-50 ... 150 °C			
<b>Continuous:</b>	-40 ... 70 °C			
<b>Short term:</b>	-60 ... 302 °F			
<b>Continuous:</b>	-40 ... 158 °F			
Accessories:				
MP 8060	Mounting plate			

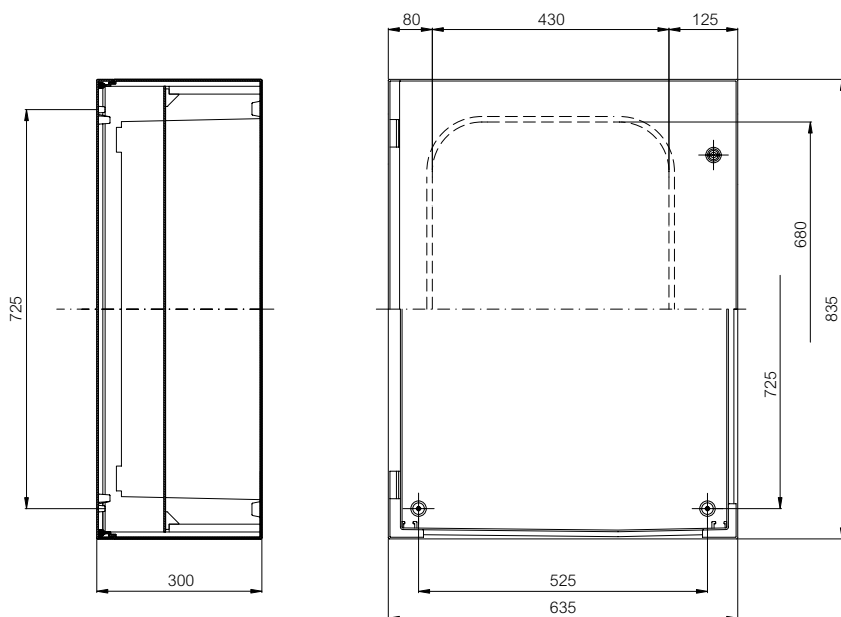

CAB 806030