

HAKKO HEATING GUN

Heating Gun



No. 882 1000 W

Temperature is freely adjustable within the range of room temperature to 450°C.

Applications

Drying of paints	Perfect for drying paints locally
Shrink film	Heat shrinking of films
Shrink tubing	Heat shrinking of electric wire covers
Putty	Repair work using putty including repairs of automotive bumpers
Interior decor	Vinyl cloth, floor materials, flooring work
Plastic moldings / Rubber products	Bending, fitting, and assembly of plastic products (heat plasticity)
PVC pipe	Bending work
Stone	Drying of stone after polishing, drying of surface-lustering agent, drying of paint finish, drying before rubber lining (printing of names, etc.)
Removal of labels	—
Thermosetting resin	Expediting setting
Defrosting	Heating water pipes and machinery frozen in winter

Packing List


882	Unit, Instruction manual
-----	--------------------------

Specifications


Model No.	882
Power consumption	1,000 W
Maximum temperature*	Room temperature to 450°C (variable)
Air velocity	360 m/min.
Air flow	0.2 m ³ /min.
Dimensions	285 (W) × 185 (H) × 70 (D) mm
Weight**	0.7 kg

* Approximate value measured at a point 10 mm from the hot air outlet


** Without cord

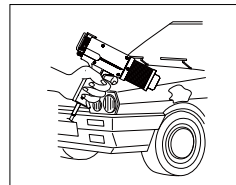


Spot drying of coating material and coating putty

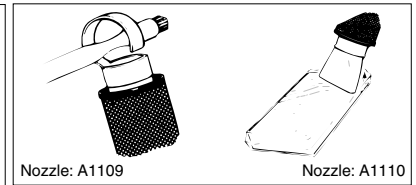

Heating of shrink tubing and shrink film

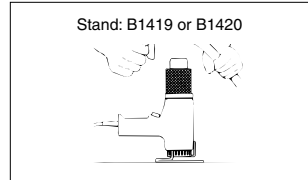

Bending and welding of PVC pipes

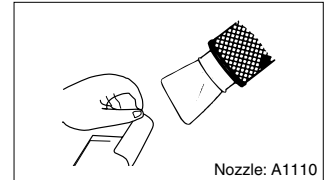

Removing stickers, labels, and gummed tape