



400W PSU 80 Plus

12cm Black Fan Active PFC TW Caps UK Lead



Features

Black Outlook - Elegant black PSU casing with fully black mesh cables.

ATX12V ver.2.4 - Compliant with the latest ATX12V ver.2.4

Single 12V Rail - Single 12V rail for high compatibility and extremely high current output.

Long Cabling - 20 + 4 Pin cable length up to 500mm and 4 + 4 Pin up to 550mm are easy for high-end tower chassis installation.

One PCIe - One PCIe 6 + 2 Pin connector for mid-range graphic card installation.

4 Sata - Up to 4 Sata connectors supports a number of hard drives.

12cm Silent Fan - 12cm silent black fan with a smart thermal fan speed control circuit.

Fully Protection - Fully protection functions with OVP/UV/OPP/SCP/SIP.

Fully Safety - Safety and EMC certified by CE and TUV.

ECO friendly - ECO friendly by RoHS and Erp2014.

80+ Certified - 80 Plus 230V EU certified.

Retail Box Packed - Colour box retail packaging

Warranty - Two years warrant

Please Note - This PSU was designed for desktop systems according to Intel's Desktop Platform Form Factors. Usage outside of these parameters, including cryptocurrency mining, might cause overheating, malfunction, or damage to your equipment and will void your warranty.

Connectors



4+4 Pin 12V Connectors x 1




SATA Connectors x 4



4-Pin Molex Connectors x 2



6+2 Pin PCI-e Connectors x 2

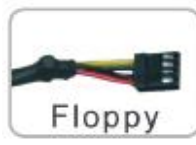

Floppy Drive Connector x 1

20+4 Pin Main Connectors x 1



400W PSU 80 Plus

12cm Black Fan Active PFC



ENGLISH



AC INPUT: 200-240VAC 3A 50Hz

DC	+3.3V	+5V	+12V ₁	-12V	+5 _{VSB}
Output	16A	15A	30A	0.3A	2.5A
Max			400W		