




## Datasheet

### RS PRO Ethernet to BNC Ethernet Converter

Stock number: 190-1827

EN

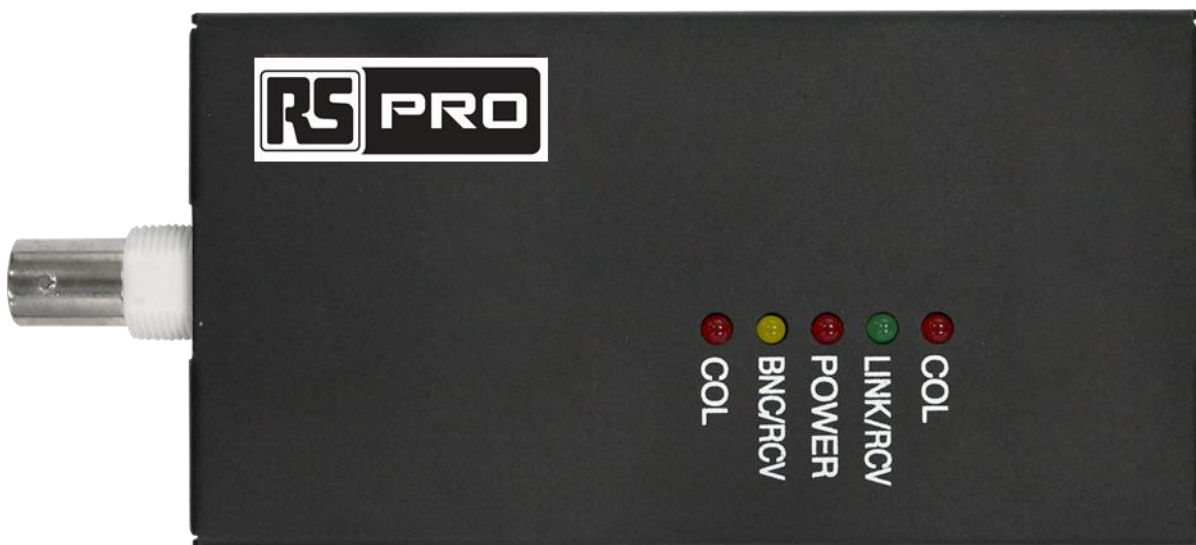

## Features

- 10M Ethernet 10Base-T/2converter
- RJ-45 connector for UTP interface
- UTP CAT 3 or 5 cable up to 100-meter

## Specifications

External Power:	Input 110V or 220V AC Output 12V DC, 1 Amp
Technique:	Baseband
Lan Expansion:	Twisted Pair expand upon to 4 level
	Thinnet up to 30 Hubs
Topology:	Star
Protocol:	CSMA/CD

- IEEE Standard: IEEE802.3 10Base-T/10Base-2
- Interface Connector
  - 1\* RJ-45 Jack from (Hub/station) select switch,
  - 1\* BNC socket to 10 Base-2
- Maximum cable Length
  - UTP: 100m
  - Coaxial: 185m per segment
- Data Transfer Rate: 10Mbps
- LED Indicator: Col, Link/RCV, Power, BNC/RCV, Col
- Power Supply: External Power Adapter DC5V1A
- Environment
  - Operating temperature : 0°C to 55°C
  - Operating Humidity:10% to 90% (Non-Condensing)
- Dimension: 104 \* 55 \* 20 mm
- Certification: FCC, CE

## Application

