




Type label identification, thermal transfer

Helatag 1204 (Silver-matt)

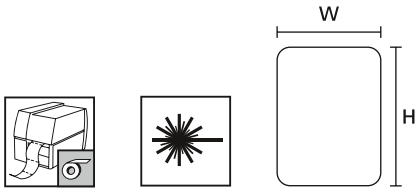

TYPE	Width (W)	Height (H)	Width of Liner (WL)	Labels per Row	Pack Cont.	Colour	Article-No.
TAG65TD1-1204-SR	76.2	36.5	82.0	1 pc.	1,000 pcs.	Silver-matt (MTSR)	596-12065
TAG62TD1-1204-SR	76.2	50.8	82.0	1 pc.	500 pcs.	Silver-matt (MTSR)	596-12062
TAG64TD1-1204-SR	88.9	36.5	95.0	1 pc.	1,000 pcs.	Silver-matt (MTSR)	596-12064
TAG97TD1-1204-SR	101.6	74.0	106.0	1 pc.	500 pcs.	Silver-matt (MTSR)	596-71204
TAG02TD1-1204-SR	104.0	12.0	104.0	1 pc.	5,000 pcs.	Silver-matt (MTSR)	596-21204
TAGR3TD1-1204-SR	104.0	75,000.0	108.0	1 pc.	75.0 m	Silver-matt (MTSR)	596-31204

All dimensions in mm. Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.



For product specific approvals and specifications please refer to the Appendix.

Asset identification label, thermal transfer

Helatag 1206 (White gloss)

This white label is scratch-resistant and is ideal for usage as identification or name plate in industrial environments. The high temperature range suits a wide range of applications on flat surfaces. The adhesive is also suitable for critical surfaces like plastic and paint.

Designing and printing labels is simple and users can quickly print out professional labels in a matter of moments when using TagPrint Pro labelling software.

Features and benefits

- Ideal for machinery operating in high temperature areas (up to +150 °C)
- For applications on flat surfaces
- Chemical resistant polyester foil
- For permanent and ageing-resistant identification
- Barcodes and alphanumeric text remain pin sharp on this high quality material
- White colour guarantees a suitable contrast for all barcode scanners to read printed barcodes



Helatag labels for permanent asset identification.


MATERIAL	Type 1206, Polyester (PET), white gloss (GSWH)
Operating Temperature	-40 °C to +150 °C
Curing Temperature	from 0 °C
Adhesive	Acrylic
Thickness of Foil	50 µm
Chem. Material Properties	Excellent resistance to water, alcohol, most oils, greases, fuel, aliphatic solvents, weak acids, salts and alkalis.
Recommended Ribbon Type	TT822OUT
Thermal Transfer Printer	TT430, TT4030





Asset identification label, thermal transfer

Helatag 1206 (White gloss)

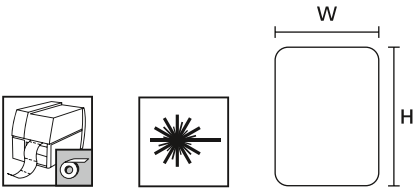

TYPE	Width (W)	Height (H)	Width of Liner (WL)	Labels per Row	Pack Cont.	Colour	Article-No.
TAG71TD6-1206-WH	12.7	11.1	101.6	6 pcs.	15,000 pcs.	White gloss (GSWH)	596-12671
TAG13TD4-1206-WH	19.1	6.4	101.6	4 pcs.	10,000 pcs.	White gloss (GSWH)	596-12061
TAG16TD3-1206-WH	22.9	6.4	80.0	3 pcs.	10,000 pcs.	White gloss (GSWH)	596-12616
TAG61TD3-1206-WH	25.4	4.8	89.0	3 pcs.	10,000 pcs.	White gloss (GSWH)	596-12661
TAG01TD3-1206-WH	25.4	6.4	89.0	3 pcs.	7,500 pcs.	White gloss (GSWH)	596-01120
TAG34TD3-1206-WH	25.4	9.5	85.1	3 pcs.	7,500 pcs.	White gloss (GSWH)	596-12634
TAG15TD3-1206-WH	25.4	12.7	85.1	3 pcs.	7,500 pcs.	White gloss (GSWH)	596-12615
TAG31TD3-1206-WH	25.4	19.1	85.1	3 pcs.	5,000 pcs.	White gloss (GSWH)	596-12631
TAG35TD3-1206-WH	31.8	9.5	101.6	3 pcs.	7,500 pcs.	White gloss (GSWH)	596-12635
TAG17TD2-1206-WH	38.1	6.4	85.1	2 pcs.	5,000 pcs.	White gloss (GSWH)	596-12617
TAG27TD2-1206-WH	38.1	19.1	85.1	2 pcs.	2,500 pcs.	White gloss (GSWH)	596-12627
TAG67TD2-1206-WH	38.1	31.8	85.1	2 pcs.	2,500 pcs.	White gloss (GSWH)	596-12667
TAG69TD2-1206-WH	40.6	22.9	89.0	2 pcs.	2,500 pcs.	White gloss (GSWH)	596-12669
TAG77TD1-1206-WH	50.8	22.9	55.0	1 pc.	2,000 pcs.	White gloss (GSWH)	596-71206
TAG73TD1-1206-WH	50.8	25.4	55.0	1 pc.	2,000 pcs.	White gloss (GSWH)	596-12673
TAG68TD1-1206-WH	63.5	25.4	69.0	1 pc.	2,000 pcs.	White gloss (GSWH)	596-12668
TAG63TD1-1206-WH	63.5	38.1	70.0	1 pc.	1,000 pcs.	White gloss (GSWH)	596-12663
TAG76TD1-1206-WH	63.5	50.8	70.0	1 pc.	500 pcs.	White gloss (GSWH)	596-61206
TAG4TD1-1206-WH	65.0	20.0	70.0	1 pc.	2,500 pcs.	White gloss (GSWH)	596-41206
TAG72TD1-1206-WH	69.9	31.8	76.0	1 pc.	1,000 pcs.	White gloss (GSWH)	596-12672
TAG65TD1-1206-WH	76.2	36.5	82.0	1 pc.	1,000 pcs.	White gloss (GSWH)	596-12665
TAG62TD1-1206-WH	76.2	50.8	82.0	1 pc.	500 pcs.	White gloss (GSWH)	596-12662
TAG64TD1-1206-WH	88.9	36.5	95.0	1 pc.	1,000 pcs.	White gloss (GSWH)	596-12664

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.



For product specific approvals and specifications please refer to the Appendix.