


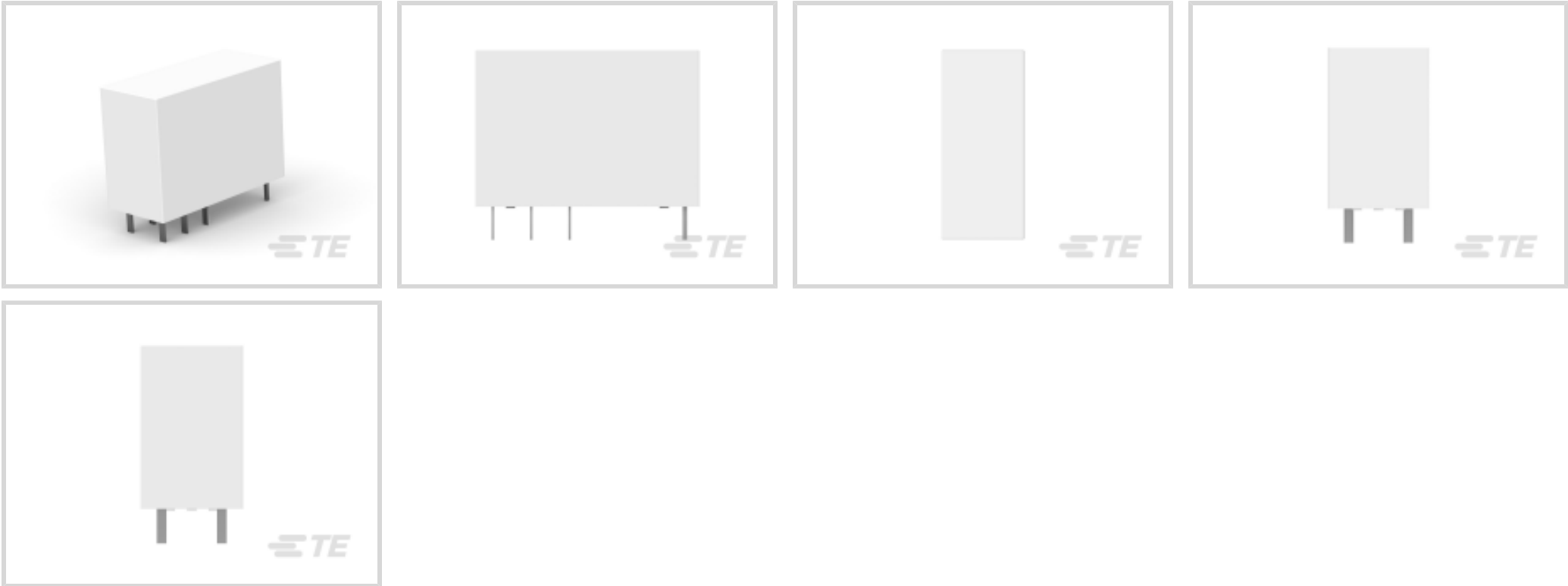

All STD SCHRACK RZF Power Relays (0)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2018 (181) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Customers Also Bought



TE Part #2301859-2
ZQSFP+ STACKED RECEPTACLE
ASSEMBLY 2X2

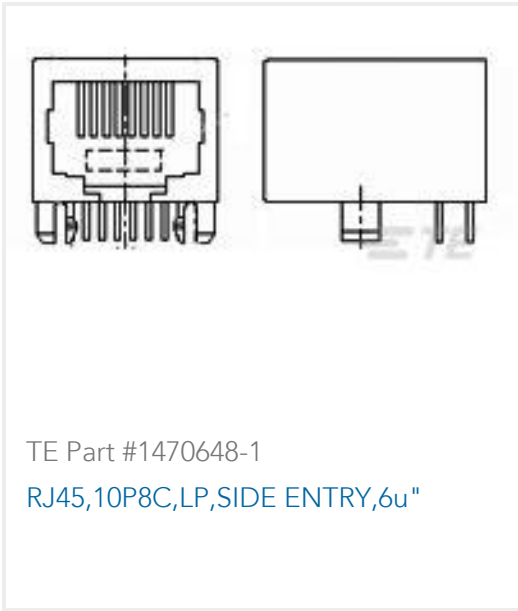

TE Part #1470648-1
RJ45,10P8C,LP,SIDE ENTRY,6u"



TE Part #766404-1
DRW HDR ASSY., R.A. 24 SL



TE Part #3-1734857-4
PCI EXP STRADDLE 98P WHT 15u"



TE Part #1735482-5
0.8FH,R17H.5,120,08/Sn,TR,SC



TE Part #2041549-1
SOCKET ASSY, DMD 350, T/R, G/F



TE Part #2319757-1
DUAL LGA,257 POS, DMD SOCKET



TE Part #6450361-4
MBXL R/A RCPT SOLDER 48S18P



TE Part #1-1649399-4
OZ-SH-124L1,200



TE Part #2041529-1
Std HDMI, RA, SMT, Panel grd, Flange

Documents

Product Drawings

OZ-SH-112L1,200

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-1649399-2_G.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-1649399-2_G.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-1649399-2_G.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.



Datasheets & Catalog Pages
OZ_OZT Series Relay Data Sheet - English
English

Product Specifications
Product Specification
Japanese
Definitions General Purpose Relays
English