

Double ended ring spanner, deep offset Metric, 2M

Double ended deep offset box spanner in Metric sizes.

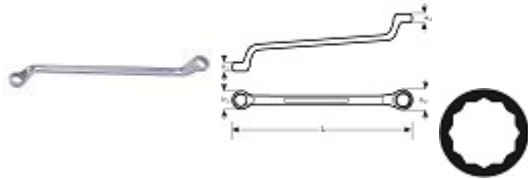
DIN 838 / ISO 1085 / ISO10104






Finish: nickel and chrome-plated, sizes up to 36x41 fine-polished.

Material: VANADIUM-EXTRA.

Dynamic-Drive-Profile up to 36x41 mm.

SB = Retail packed on a plastic info card.



				L mm	a1xa2 mm	b1xb2 mm	
2M-6-7	1001209	5	6x7	165	5x6	10.5x12	40
2M-8-9	1001216	5	8x9	180	6x6.5	13x14.5	55
2M-8-10	1001506	5	8x10	180	6x6.5	13x14.5	65
2M-10-11	1001223	5	10x11	190	7x7.5	16.1x18.1	85
2M-10-13	1001513	5	10x13	220	7.9x9.1	16.6x20.0	120
2M-12-13	1001230	5	12x13	210	8x8.5	18.7x20.8	125
2M-13-17	1343972	5	13x17	243.4	9.5x10	20.8x27	180
2M-14-15	1001247	5	14x15	225.8	8.5x9.5	22.5x24.5	155
2M-16-17	1001254	5	16x17	245.5	9.5x10	25x27	200
2M-16-18	1001575	5	16x18	245.5	9.5x10	25x27	190
2M-17-19	1000844	5	17x19	265.5	10.5x11	27.5x29.5	255
2M-18-19	1001261	5	18x19	265.5	10.5x11	27.5x29.5	260
2M-19-22	1000868	5	19x22	290.5	11.5x12	30.6x33.7	340
2M-20-22	1001278	5	20x22	290.5	11.5x12	30.6x33.7	350
2M-21-23	1001285	5	21x23	305.7	12x13	32.7x35.75	390
2M-22-24	1001612	5	22x24	305.7	12x13	32.7x35.75	450
2M-24-26	1001292	5	24x26	325.8	13x14	35.75x40	470
2M-24-27	1000899	5	24x27	325.8	13x14	35.75x40	530
2M-25-28	1001308	5	25x28	335.9	13.5x14.5	37.8x43	510
2M-27-30	1001636	5	27x30	351	14x15	42x46.1	610
2M-27-32	1001322	5	27x32	353	14x16	42x49.5	620
2M-30-32	1000929	5	30x32	361.5	15x16	46.5x49.5	650

2M-32-36	1001667	1	32x36	416	17x18	49.5x55.5	850
2M-36-41	1001681	1	36x41	444.25	18.5x19.5	55x61.5	1170
2M-41-46	1001704	1	41x46	482.5	20x21	61.5x67.5	1450
2M-46-50	1001711	1	46x50	540.75	21x22	67.5x74	1700