



Brand of NTN corporation


Technical data

BBE25UU-RL

Standard ball bushings closed



VISUAL (S)

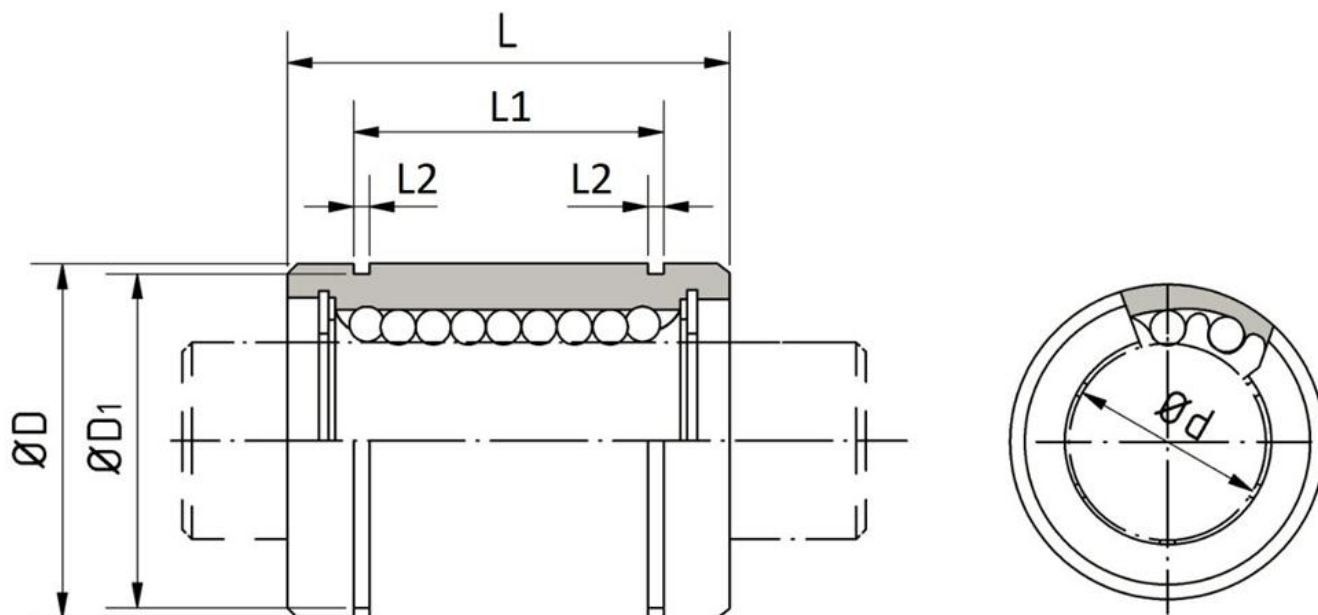

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
Re-lubrication and fixing hole	Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

Re-lubricable	Oui/Yes
d - Internal diameter	25 mm
d - Internal diameter tolerance	0,011/-0,001
D - External diameter	40 mm
D - External diameter tolerance	0/-0,011
L - Length	58 mm
L - Length tolerance	0/-0,3
L1	44,1 mm
L1 tolerance	0/-0,3
D1 - Diameter	37,5 mm
L2	1,85 mm
Number of ball rows	6
Mass	0,235 kg

PRODUCT PERFORMANCE

Cmin	0,908 kN
Cmax	1,162 kN
C0min	1,57 kN
C0max	2,01 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY

Reference	BBE25UU-RL
Image	BBE-RL_1.JPG, BBE-RL_3.JPG



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

ESHOPDONOTDISPLAY	
Send to Eshop	Yes
Send to Paper Catalog	Yes
Tracepart	Oui/Yes

