


Plug AM-TOP® - Part no. 252

- screw terminals
- single part body
- cable gland and sealing
- strain relief and protection against kinking

| | |
|-----------------------|-----------------|
| Protection type | IP 44 |
| Ampere | 16A |
| Poles | 4p |
| Voltage | 400V |
| Hertz | 50-60 Hz |
| Earth position | 6h |
| Contact | standard |
| Connection technology | Screw terminals |



Std. Pack. 10 Qty.

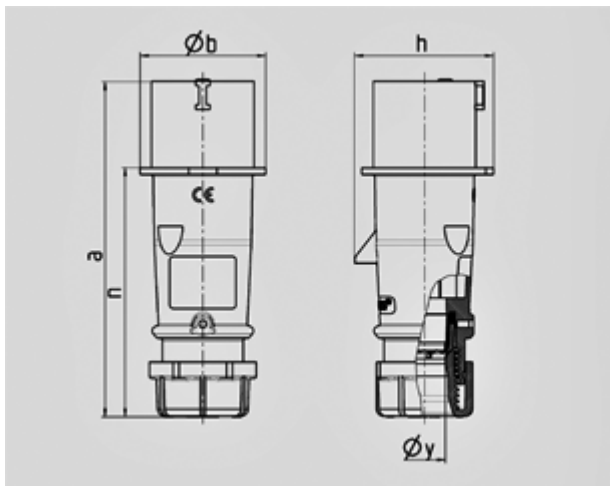

| Drawing | Amp. | 16 | | | 32 | | |
|--------------------------------------|-------|-------|-------|-------|-----|-----|------|
| | | 3 | 4 | 5 | 3 | 4 | 5 |
| 2 MB 217 | Poles | | | | | | |
| Dim. in mm | a | 142 | 147 | 147 | 186 | 186 | 180 |
| | b | 53 | 59 | 67 | 70 | 70 | 77 |
| | h | 59 | 69,4 | 76 | 81 | 81 | 89,5 |
| | n | 105,2 | 110,5 | 110,5 | 141 | 141 | 135 |
| | y | 14,5 | 16 | 16 | 22 | 22 | 22 |
| Terminal for cond. cross | | 1 | 1 | 1 | 2,5 | 2,5 | 2,5 |
| section (mm ²) min.-max. | | -2,5 | -2,5 | -2,5 | -6 | -6 | -6 |