


FEATURES

- Bright, flicker-free and evenly distributed light
- Adjustable brightness via emergency, DALI, Switch Dim and - 1-10V options
- Lightweight and durable
- Cost effective and energy efficient
- Stylish minimalist design

RS PRO 36 W LED Ceiling Light, 220 → 240 V LED Panel, 595 mm Long RS PRO Ceiling Lights

RS Stock No.: 179-7628

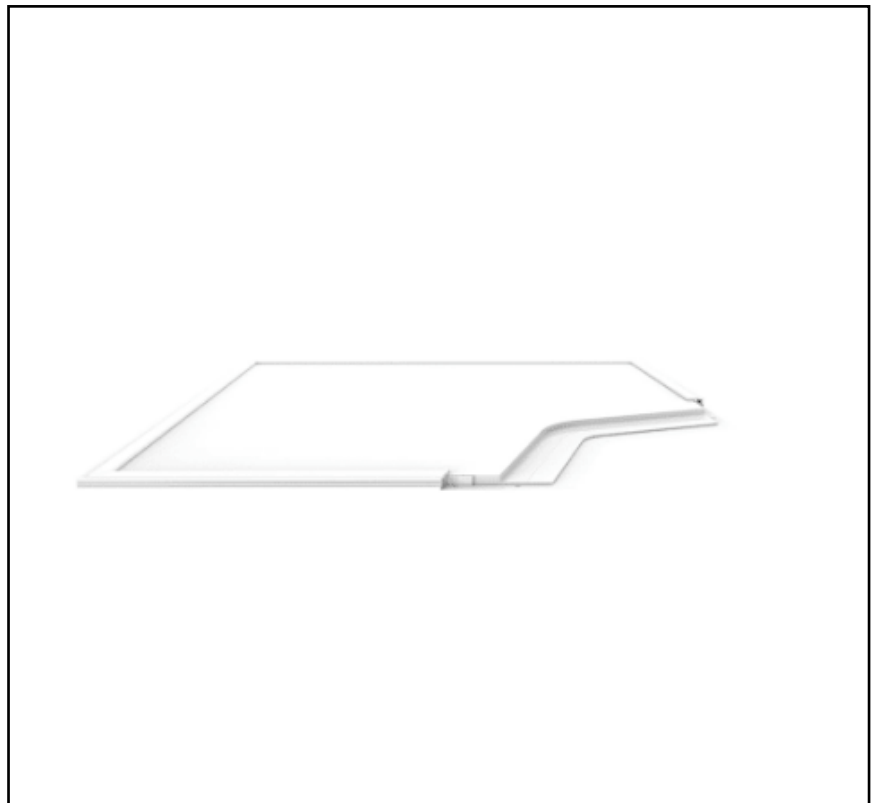

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Introducing the panel - light series from RS PRO, an economical and versatile solution for all office and corridor environments. RS PRO light panels feature “plug and play” drivers to allow for quick installation in ceiling grids. This ensures that the panels can be easily installed, quickly and efficiently.

General Specifications

Type	LED Panel
Lamp Type	LED
Colour Temperature	6000K
Life Hours	30000h
Anti-Corrosive	No
PIR Included	no
Applications	Ceiling lights are a very common type of light fixture which can be fitted to the ceiling in: Industrial areas; Multi-storey car parks; Workshops, warehouses and factories; Garages
Construction	Metal
CRI	>80
Dimmable	Yes

Electrical Specifications

Wattage	36W
Voltage Rating	220V to 240V
Electrical Class	2
Power Factor	>0.9

Mechanical Specifications

Length	595m
Width	595mm
Depth	10mm
Weight	36kg
Beam Angle	120°
Lumen Output	3500lm
Ra	>80

Approvals

Compliance/Certifications	RoHS Certificate Of Compliance
----------------------------------	--------------------------------

