


suction cup holder ESH-HB-4-PK

Part number: 189210

FESTO

without height compensator, vacuum connection at side.

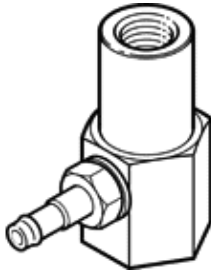

Data sheet

Feature	Value
Volume	0.416 cm ³
Assembly position	Vertical
Design structure	Vacuum connection at side
Correlation to suction-cup holder	Size 4
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:~:]
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	25 g
Mounting type	with internal (female) thread
suction cup mounting	M6
Vacuum connection	PK-4
Materials note	Conforms to RoHS
Material seals	NBR Steel
Material bracket	POM Heat-treatment steel High alloy steel