 



# FLUORESCENT LAMP

F40W/2FT/T12



## OUTLINE:

Dimensions in mm

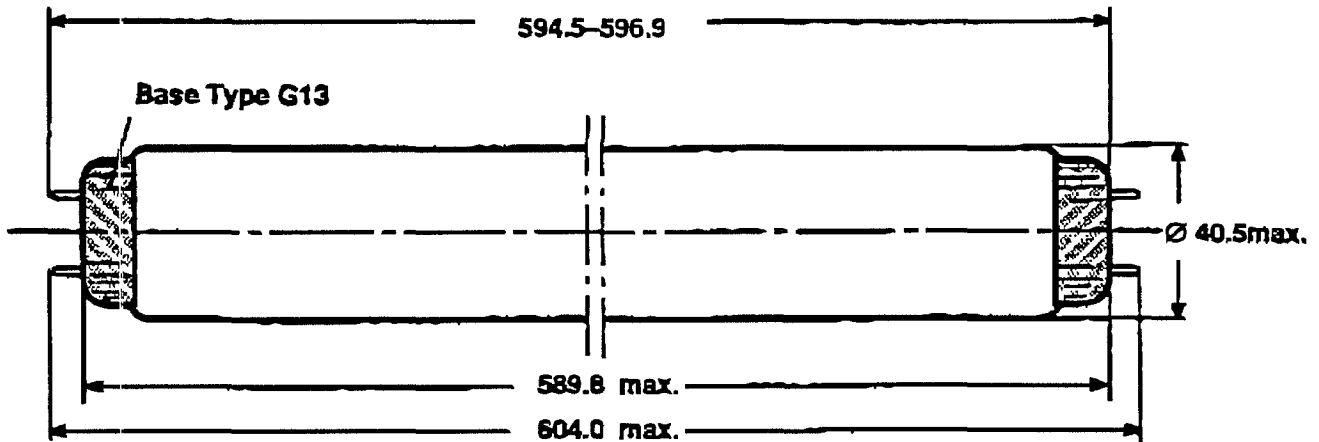

## ELECTRICAL DATA:

		Nominal Value	Min.	Max.
Lamp Wattage	(W) :	40.0	34.7	39.9
Lamp Voltage	(V) :	47.0	40.0	54.0
Lamp Current	(A) :	0.880		

## OPERATING CONDITIONS :

	Ballast Type	Starter
Single Lamp Circuit	40W	FS-11, COP/H-20, COP/H-46
Tandem Circuit	80W	FS-22

## PHOTOMETRIC DATA:

COLOUR	CODE	Luminous flux		CRI Class	Colour Temp. (K)
		lm			
WARM WHITE	WW 129	2000		3	3000
COOL WHITE	CW 133	1900		2B	4300
WHITE	W 135	2000		3	3500
DAYLIGHT	D 154			3	6500
BL350	BL 350	not suitable for lighting applications			

**APPLICATION:** For further lamp data refer to IEC81 / EN 60081, most recent edition.

**ATTENTION:** The product must be used with suitable operating equipment and in accordance with the specified data.

Issued by : ERLANGEN  
Date : 11.81  
Revision date: 09.07.91

## DATA SHEET

Specification Nbr : 4212A  
Supersedes : 4212 11.81  
Page 1 of 1

SYLVANIA reserves the right to change data and specifications without notice.  
Data for guidance only.

**SYLVANIA**

**GTE**