



SSD M.2 2280 SATA III

The M.2 2280 form factor brings the speed and reliability of Solid State Drives to a much lower profile so you can add those benefits to laptops and ultrabooks. The form's increasing popularity means that many desktop motherboards are also compatible with these super fast, super quiet, super reliable drives.

480MB/s Read*
400MB/s Write*


* Based on internal testing;
performance may vary depending on
host device.

- M.2 2280 form factor with SATA III 6Gbps interface (backwards compatible with SATA 3Gbps and SATA 1.5Gbps)
- Supports 'M' & 'B' Key sockets
- Performance: Faster boot than HDD, Faster access to applications, enhanced productivity and increased efficiency
- Fully compatible with devices and OS that support the SATA standard with M.2 M and B socket
- Shock resistance - No moving parts enable the product to be used in tougher conditions
- Supports S.M.A.R.T. - Self-Monitoring, Analysis and Reporting Technology
- RoHS and UKCA compliant
- CE and FCC tested
- 3 year warranty or TBW - whichever is earlier applies



PRODUCT SPECIFICATION:

Capacity (GB)	128
Form Factor	M.2
Interface	Serial ATA III
S.M.A.R.T. Support (Y/N)	Y
TRIM Support (Y/N)	Y
Protection Features	Shock resistant

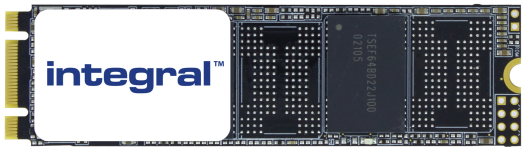

TECHNICAL SPECIFICATION:

Read Speed (MB Per Second)	480
Write Speed (MB Per Second)	400
Data Transfer Rate (GB Per Second)	6
Mean Time Between Failures (MTBF) (Hour)	1500000

	PART CODE		BARCODE (EAN)	
128	INSSD128GM280		5055288444867	
	HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	WEIGHT (g)
PRODUCT	22	80	2.25	6
PACKED	64	120	8	15