


# 1U fibre optic patch panels pre-loaded with coupling bushings

## 210mm depth ST, SC and ST to SC hybrid patch panels

Dimensions : 43mm x 210mm x 429mm (HxDxW)  
483mm W including mounting brackets

Colour : Black

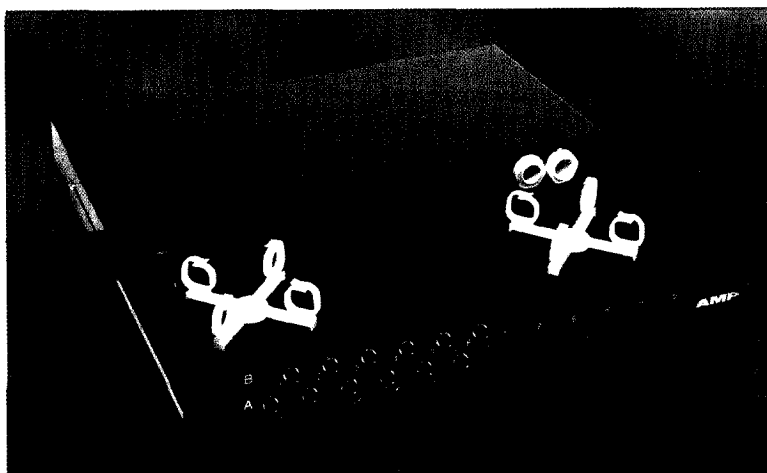

ST patch panel

Description	Part Number
4 Port ST	5-1206480-4
8 Port ST	6-1206480-4
12 Port ST	2-1206480-4
16 Port ST	7-1206480-4
24 Port ST	4-1206480-4

Description	Part Number
4 Port (2 Duplex) ST - SC Hybrid	5-1206483-4
8 Port (4 Duplex) ST - SC Hybrid	6-1206483-4
12 Port (6 Duplex) ST - SC Hybrid	2-1206483-4
16 Port (8 Duplex) ST - SC Hybrid	7-1206483-4
24 Port (12 Duplex) ST - SC Hybrid	4-1206483-4

Note: SC Interface is on the outside of the patch panel.

Description	Part Number
4 Port (2 Duplex) SC	5-1206505-4
8 Port (4 Duplex) SC	6-1206505-4
12 Port (6 Duplex) SC	2-1206505-4
16 Port (8 Duplex) SC	7-1206505-4
24 Port (12 Duplex) SC	4-1206505-4

Note: Cable glands, fibre/cable management and splice holders are supplied pre-fitted.

## Installation Guidelines:

### Tools required:

- Cable strippers and cutters
- Fibre cleave tool
- Splice protectors (fusion splice only)
- Screwdriver (crosshead)

### Installation Procedure:

- Thread cable into gland, leaving approximately 1m exposed
- Strip cable outer jacket and strain members (1m)
- Screw gland tight (50mm from jacket end)
- Strip buffer (tight buffer types only)
- Cleave fibre
- Splice to relevant pigtail
- Apply protector (fusion version only)
- Loop fibres into management rings
- Test