



ENGLISH

Datasheet

Aluminium Enclosure, IP66, Shielded, Flanged, 149.8 x 100.2 x 35.6mm

RS Stock number 621-4918




Description:

IP66 Flanged - Powder Coated

- Aluminium alloy LM24 die cast boxes with pre-drilled mounting flanges
- Self adhesive rubber seals provide IP66 rating when secured to the box lids
- Integral PCB guides
- EMI/RFI screening
- Length External dimension includes flanges

Specifications:

Colour:	Grey
Body Material:	Die Cast Aluminium
External Dimensions:	149.8 (length) x 100.2 (width) x 35.6 (height)mm
IP Rating:	IP66
Lid Colour:	Grey
Flanged:	Yes
Shielded:	Yes

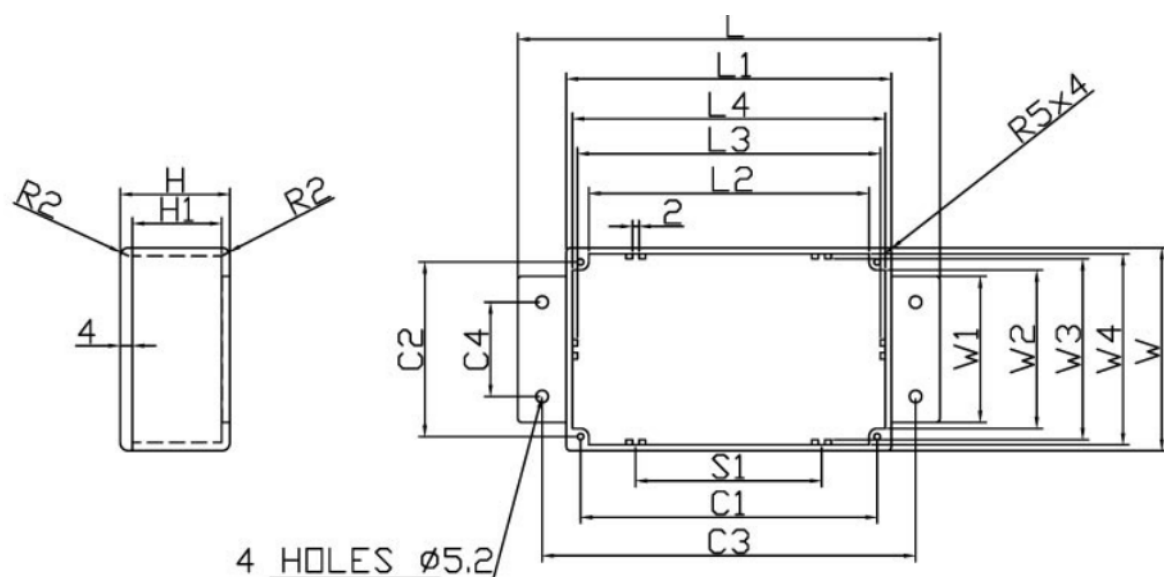

L	L1	W	W1	H	C1	C2	C3	C4	S1	L2	L3	L4	W2	W3	W4	H1
149.8	120.1	100.2	80.0	35.6	108.2	88.3	137.0	60.0	45.2	101.8	112.2	116.5	81.9	91.7	95.9	28.8