


# Rittal – The System.

Faster – better – everywhere.

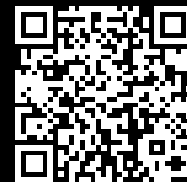

## VX 5302.034

### Slide rail, 2 U, static installation, heavy duty

State: 9/12/2025 (Source: [rittal.com/uk-en](https://www.rittal.com/uk-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 5302.034 - Slide rail, 2 U, static installation, heavy duty for VX IT

For mounting between a front and rear pair of mounting angles for 482.6 mm (19") standard mounting angles and 482.6 mm (19") dynamic mounting angles in the VX IT.



## Features

|                      |                                                                                                                                                                     |
|----------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Model No.            | VX 5302.034                                                                                                                                                         |
| Product description  | Side system punchings for mounting accessories and cooling components that expel to the side.                                                                       |
| Benefits             | Simply locate into the system punchings of the 482.6 mm (19") mounting brackets after adjusting the required 482.6 mm (19") distance between levels                 |
| Applications         | For attachment between the front and rear 482.6 mm (19") mounting level<br>To support heavy installed equipment                                                     |
| Material             | Sheet steel                                                                                                                                                         |
| Surface finish       | Zinc-plated                                                                                                                                                         |
| Supply includes      | Assembly parts                                                                                                                                                      |
| Load capacity        | 2000 N, static                                                                                                                                                      |
| Note                 | Effective contact surface 35 mm per side                                                                                                                            |
| Installation options | for 482.6 mm (19") mounting angles, standard: Distance between levels 720/745 mm<br>for 482.6 mm (19") mounting angles, dynamic: Distance between levels 700/725 mm |

# Features

|                               |                                                                                                                |
|-------------------------------|----------------------------------------------------------------------------------------------------------------|
| Packs of                      | 2 pc(s).                                                                                                       |
| Net weight                    | 2.36                                                                                                           |
| Gross weight                  | 2.56                                                                                                           |
| PCF per pack (cradle-to-gate) | 9.8 kg CO2 eq (Cat B)                                                                                          |
| Note on PCF category          | Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared |
| Customs tariff number         | 73269098                                                                                                       |
| EAN                           | 4028177952638                                                                                                  |
| E-Number Sweden               | E7282594                                                                                                       |
| ETIM 9                        | EC002620                                                                                                       |
| ECLASS 8.0                    | 27189261                                                                                                       |