


## Features

- Made from tough, hard-wearing GRP with a grit surface for excellent slip resistance.
- The paint pigment used in the product complies with ASTM E1645-01, ensuring the product is safe and reduces the risk of lead exposure to meet regulatory standards.
- A high-quality flooring option that offers a credible alternative to steel mesh grating
- The quartz crystal-bonded top surface provides extreme durability and high slip resistance.
- Perfect for high-traffic areas or demanding, corrosive environments.
- Half the weight of steel solutions, making it easy to install with no ongoing maintenance.
- Manufactured from Type O, Orthophthalic Polyester resin, ensuring high performance and durability.
- Strong bi-directional properties allow the product to be used in various applications, making it more versatile.
- Slip test to EN 16165:2021 Annex B.
- Fire tested to EN 13501-1:2018.

## RS PRO GRP Grating - Grey 2000mm x 1000mm x 50mm

RS Stock No.: 0712644

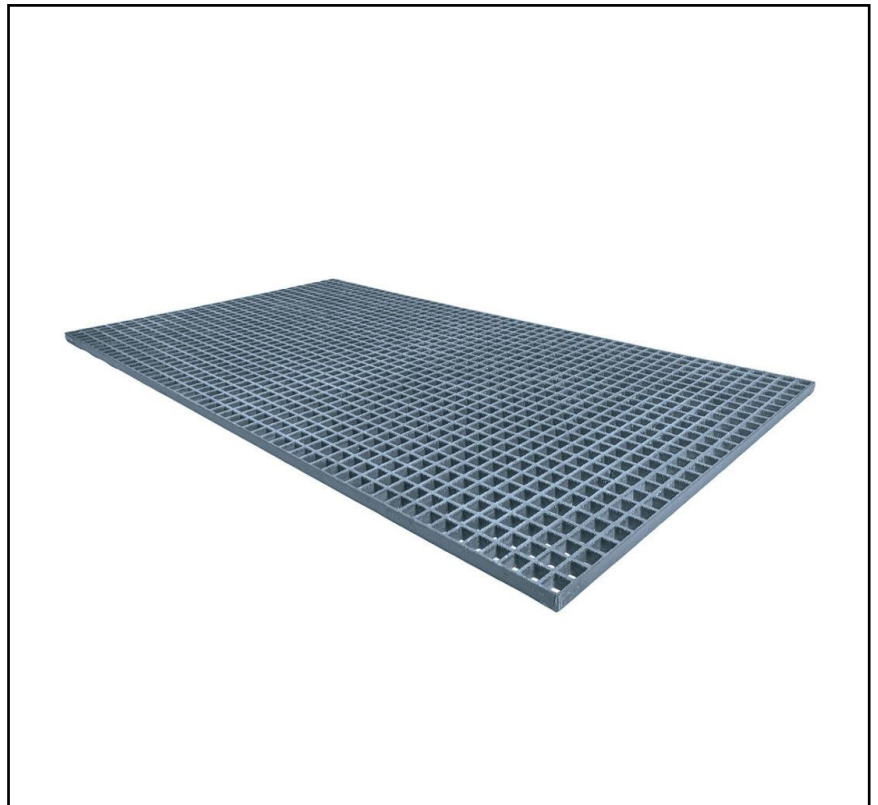

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

- Made from tough, hard-wearing GRP with a grit surface for excellent slip resistance.
- The paint pigment used in the product complies with ASTM E1645-01, ensuring the product is safe and reduces the risk of lead exposure to meet regulatory standards.
- A high-quality flooring option that offers a credible alternative to steel mesh grating.
- The quartz crystal-bonded top surface provides extreme durability and high slip resistance.
- Perfect for high-traffic areas or demanding, corrosive environments.
- Half the weight of steel solutions, making it easy to install with no ongoing maintenance.
- Manufactured from Type O, Orthophthalic Polyester resin, ensuring high performance and durability.
- Strong bi-directional properties allow the product to be used in various applications, making it more versatile.
- Slip test to EN 16165:2021 Annex B.
- Fire tested to EN 13501-1:2018.

## General Specifications

<b>Size</b>	2000 mm x 1000 mm x 50 mm
<b>Colour</b>	Grey
<b>Weight (kg)</b>	42
<b>Material</b>	GRP with quartz sand bonded on top (with resin)
<b>Surface Finish</b>	Quartz grit
<b>Min. Operating Temperature</b>	-50°C
<b>Max. Operating Temperature</b>	+60°C

## Approvals

<b>Slip test to</b>	EN 16165:2021 Annex B
<b>Fire tested to</b>	EN 13501-1:2018

## Similar Products

Stock No.	Brand	Product Name	Size	Colour	Weight (kg)
0712639	RS PRO	GRP Grating	2000 mm x 1000 mm x 25 mm	Green	26
0712640	RS PRO	GRP Grating	2000 mm x 1000 mm x 38 mm	Green	38
0712641	RS PRO	GRP Grating	2000 mm x 1000 mm x 50 mm	Green	42
0712642	RS PRO	GRP Grating	2000 mm x 1000 mm x 25 mm	Grey	26
0712643	RS PRO	GRP Grating	2000 mm x 1000 mm x 38 mm	Grey	38
0712645	RS PRO	GRP Grating	2000 mm x 1000 mm x 25 mm	Yellow	26
0712647	RS PRO	GRP Grating	2000 mm x 1000 mm x 38 mm	Yellow	38
0712648	RS PRO	GRP Grating	2000 mm x 1000 mm x 50 mm	Yellow	42