



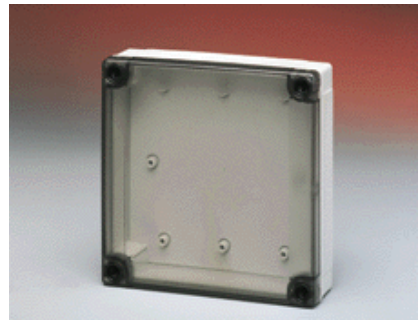

This is a sample photo.

ORDER SYMBOL: PC 125/75 LT	
EL.number Sweden: Denmark: Finland: 3420433	EAN: 6418074022325
INCLUDING: Enclosure cover with cover screws, body with mounting screws and gasket.	
APPROVALS: USA: NEMA 4, 4X, 12; UL 94-V2 EURO: IP 67; UL 94-V2 OTHERS: IEC 529	

FIBOX MNX PC

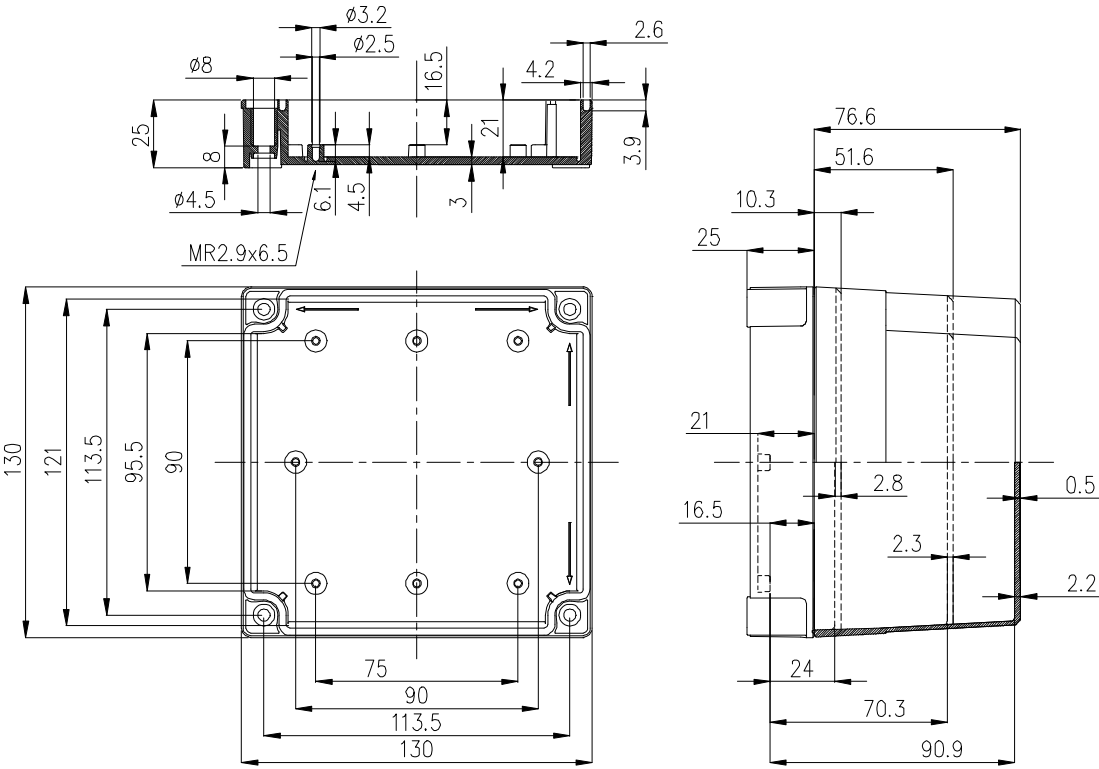

TECHNICAL INFORMATION:	
Standard colour: RAL 7035	Temp.range in cont. use: Max. +80 °C
Ingress protection: IP 67 (IEC 529)	Temp. range of material: - 40 °C - + 120 °C
Flame resistance:	

ACCESSORIES

Fastening lug	FP 22046	DIN-Rail	MIV 10
Grey Screw set	MBS HH	DIN-Rail	MIV 15
Grey Screw set	MBS HL	DIN-Rail	MIV 20
Grey Screw set	MBS LH	DIN-Rail	MIV 5
Grey Screw set	MBS LL		
DIN-Rail	MIN 10		
DIN-Rail	MIN 15		
DIN-Rail	MIN 20		
DIN-Rail	MIN 5		