


KEMET Part Number: EFF(01)-240X240T0800 Not for New Design
(UFSEFF010AT080, EFF(01)240X240T0800)

KEMET, EFF, Flex Suppressors, Noise Suppression

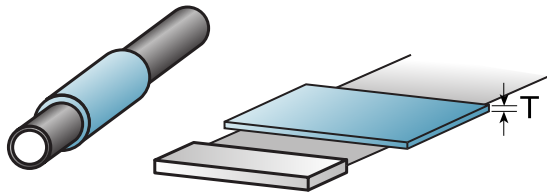

Dimensions

Sheet Size	240x240mm
T	0.1mm +/-0.05mm

Packaging Specifications

Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	0.03mm

General Information

Series:	EFF
Style:	Sheet
Description:	Flex Suppressor Halogen Free Type
Features:	Extra High Magnetic Permeability
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No. E176124
Environment:	Halogen Free, PVC Free, Lead Free
Notes:	Not recommended for new designs, please see EFF4(01)-240X240T0800 for replacement

Specifications

Temperature Range:	-40/+105°C
Magnetic Permeability:	130 μ At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.6 Atm TYP
Conductivity:	0.4 W/m K
Tensile Strength:	6.9 MPa