

# LDWB-IR212P-2

1000 TVL Super Wide Dynamic Dome Camera



The LDWB-IR212P-2 internal dome camera delivers unparalleled image quality with 1000 TVL resolution.

The cameras' unmatched wide dynamic range (WDR) capability ensures that scenes are faithfully reproduced without excessively dark or bright areas being compromised, the WDR capability also ensures much more accurate colour rendition over the entire scene.

Superior WDR also equips the camera to deal with very difficult lighting conditions, such as looking out of dark areas into brightly lit areas - even in the most demanding lighting conditions the camera delivers scene accuracy and image quality that cannot be achieved with other imaging technologies.

The aesthetic and unobtrusive housing design allows the camera to blend into almost any internal installation environment, and the three axis mount allows very flexible camera positioning.

The combination of very high resolution, superb image quality and 3D noise reduction ensure that modern DVRs can take advantage of the best possible recorded image quality whilst ensuring the best HDD storage efficiency.

## Key features

- ▶ 1000 TVL
- ▶ 3 Axis mount
- ▶ 120dB Ultra WDR
- ▶ Easy setup OSD menu system
- ▶ 12vdc / 24vac Power
- ▶ 3D Motion adaptive noise reduction
- ▶ Superb image quality
- ▶ Includes Flush Ceiling Mount

# LDWB-IR212P-2


## 1000 TVL Super Wide Dynamic Dome Camera

### Specifications

Description / Model	LDWB-IR212P-2
Sensor	1/2.8" 720P sensor
Video Format	PAL/NTSC
Resolution	1000TVL
Effective Pixels	1280(H)x1024(V)
OSD	English/Chinese/KOR/JPA
Mini Illumination	0Lux(IR ON);0.01Lux(IR OFF)
S/N Ratio	≥50dB (AGC OFF)
Sync Mode	INTERNAL
Dynamic range	120dB
White Bal	Auto/Autoext/Preset/Manual
AGC	Auto
BACKLIGHT	BLC/WDR/OFF/HLC
DNR	HIGH/MID/LOW/OFF
WDR	HIGH/MID/LOW/OFF
Spec Fun	Digital Zoom 1x-8x/Defgo/Mirror/Shading Privacy Masking 16Masks/Sensor up 50X
Shutter	AUTO/MANUAL(1/50\60-1/60,000 sec)
Voltage	12VDC/24VAC
Current	220mA±10%(IR ON);100mA±10%(IR OFF)
IR range	20m
Lens Mount	2.8-12mm
Operating Temp	-10° ~ 50°C RH90% MAX
Storage Temp	-20° ~ 60°C
Dimension	150(W) x 96mm(H)
Weight (approx)	265g

NB. Specification subject to change without notification

### Dimensions

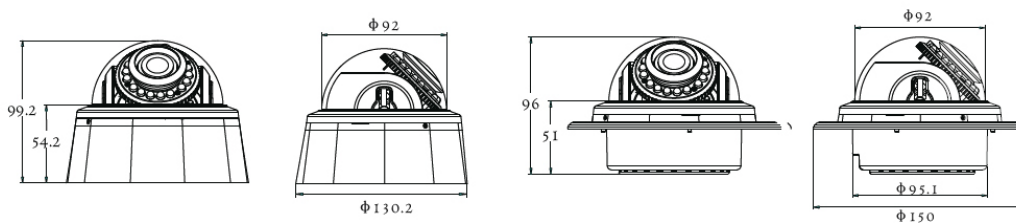

Ceiling or Wall mounted: 130mm(φ)\*99.2mm(H)

Embedded: 150mm φ\*96mm(H)

\*Illustrates Flush Ceiling Mount