


Datasheet

Fibre Optic Cable Assembly, Multi-Mode

RS Stock number 536-6361



Dimensions: (mm)

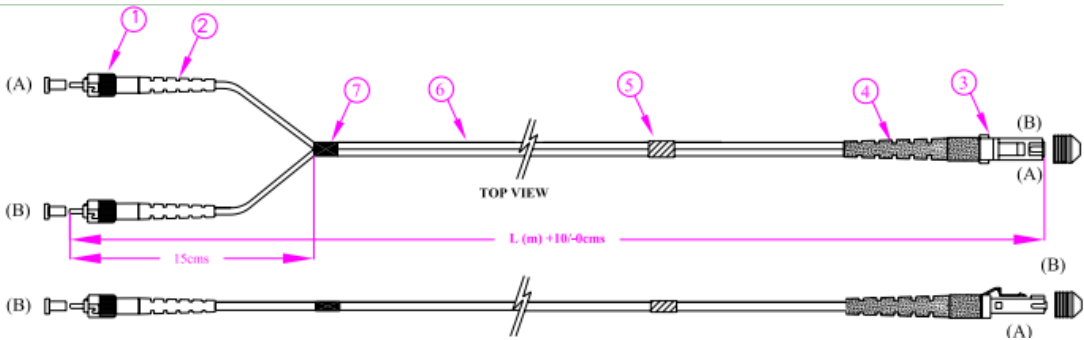

Optical Performance (IEC 61300-3-4):
Multimode (@ 1300nm)
MTRJ: Max. IL - 0.50dB Typical: 0.30dB
ST : Max. IL - 0.30dB Typical: 0.20dB
Singlemode: (@1310nm and/or 1550nm)
MTRJ: Max. IL - 0.50dB Typical: 0.30dB Return Loss: >40dB
ST : Max. IL - 0.30dB Typical: 0.20dB Return Loss: >50dB
Connector: LC clips shall be mounted on to the connector to make it duplex.
Coiling Diameter: Coiling Diameter of the patchcord shall be greater than 200mm

Id No.	Description	Ea
1.	ST Connector	2
2.	ST Boots	2
3.	MTRJ Connector	1
4.	MTRJ Boot	1
5.	Identification Label	1
6.	1.6mm Duplex Cable (L m)	1
7.	Black Tape	1