


LOVATO ELECTRIC S.P.A.

24020 GORLE (BERGAMO) ITALIA
 VIA DON E. MAZZA, 12
 TEL. 035 4282111
 TELEFAX (Nazionale): 035 4282200
 TELEFAX (International): +39 035 4282400
 E-mail info@LovatoElectric.com
 Web www.LovatoElectric.com



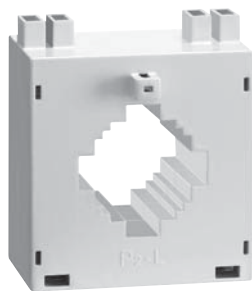


- ① TRASFORMATORI DI CORRENTE - TIPO A FORO PASSANTE
- ② CURRENT TRANSFORMERS - SOLID CORE TYPE
- ③ STROMWANDLER - AUFSTECK-TYP
- ④ TRANSFORMATEURS D'INTENSITE - TYPE A PASSAGE
- ⑤ TRANSFORMADORES DE CORRIENTE - TIPO PASANTE






DM2T... - DM3T... - DM4T...




DM2T... - DM3T...

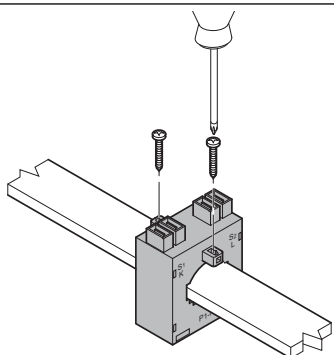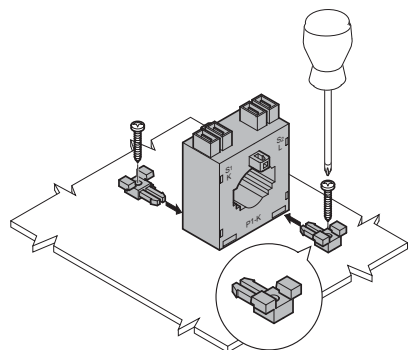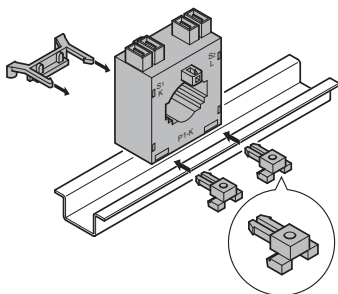





DM4T...

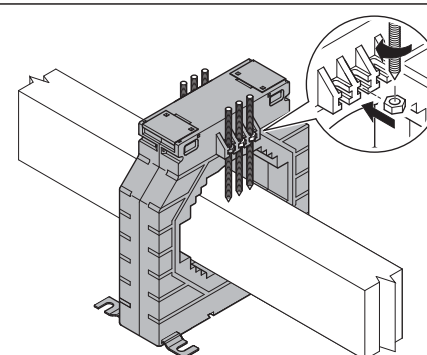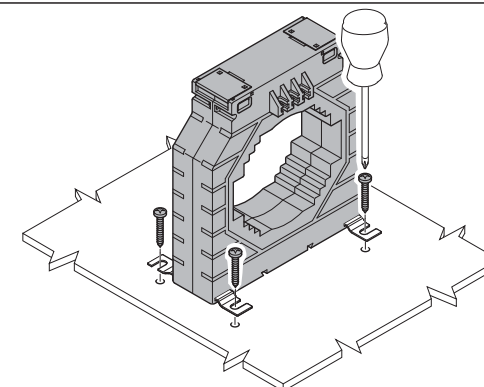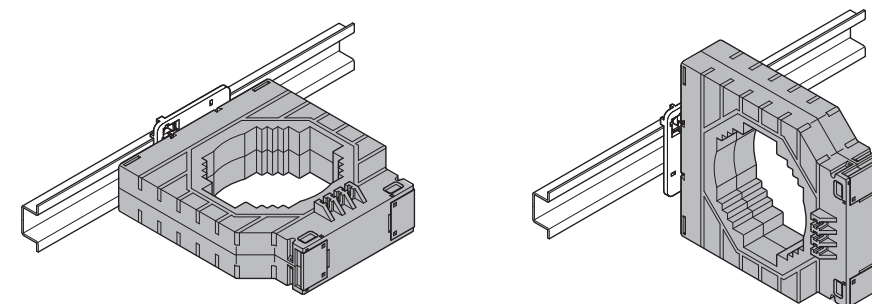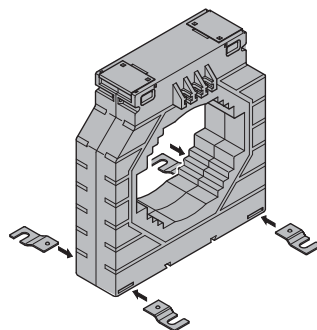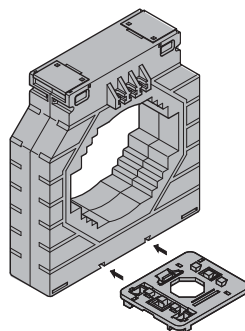


DM2T... - DM3T...

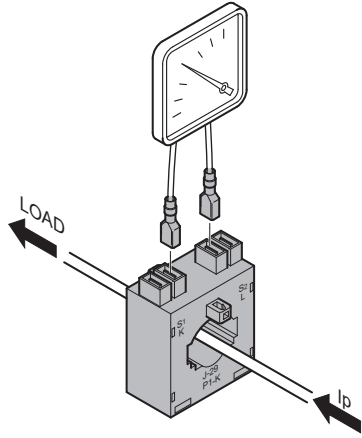

DM...T

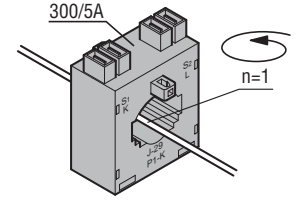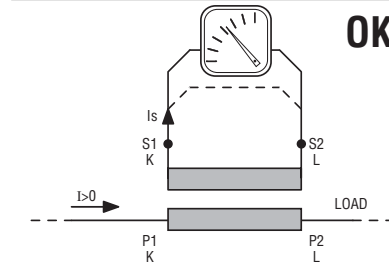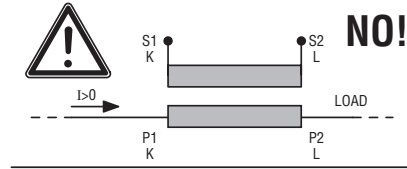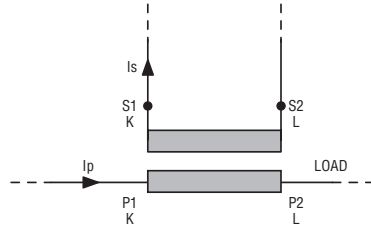


300:n/5A
300:1/5A=300/5A

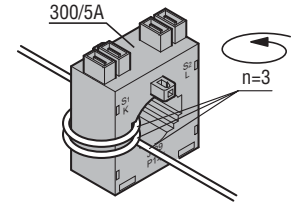


300:n/5A
300:3/5A=100/5A

DM4T...

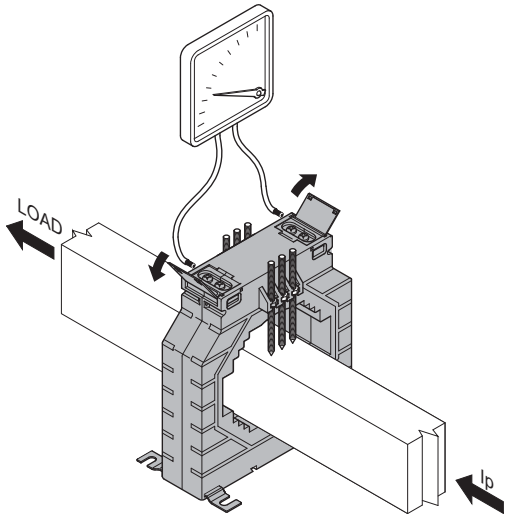


DM2T...

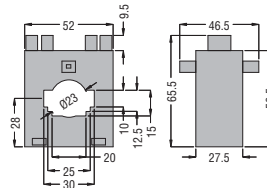

- = Ø23mm
- = 30x10mm
- = 25x12.5mm
- = 20x15mm

	Ip /5 [A]	cl./kl. 0.5 [VA]	cl./kl. 1 [VA]
DM2T 0100	100	—	1
DM2T 0150	150	—	1.5
DM2T 0200	200	—	2
DM2T 0250	250	—	2.5
DM2T 0300	300	1.5	3
DM2T 0400	400	2	3


DM3T...

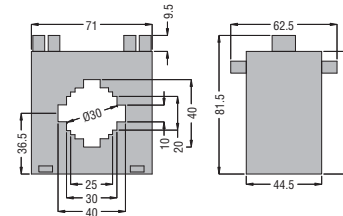

- = Ø30mm
- = 40x10mm
- = 30x20mm
- = 25x25mm

	Ip /5 [A]	cl./kl. 0.5 [VA]	cl./kl. 1 [VA]
DM3T 0200	200	—	5
DM3T 0250	250	—	5
DM3T 0300	300	2.5	5
DM3T 0400	400	2.5	5
DM3T 0500	500	2.5	5
DM3T 0600	600	5	10
DM3T 0800	800	5	10
DM3T 1000	1000	5	10

DM4T...

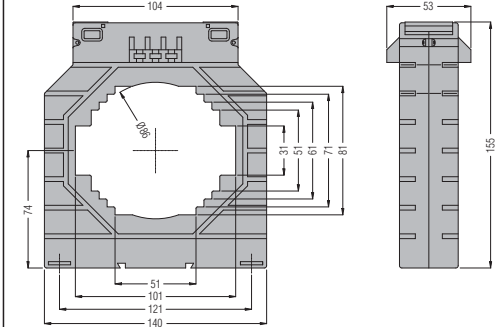

- = Ø86mm
- = 100x30mm
- = 80x50mm
- = 70x60mm

	Ip /5 [A]	cl./kl. 0.5 [VA]	cl./kl. 1 [VA]
DM4T 1000	1000	10	20
DM4T 1200	1200	15	30
DM4T 1250	1250	15	30
DM4T 1500	1500	20	30
DM4T 1600	1600	20	30
DM4T 2000	2000	30	45
DM4T 2500	2500	35	45
DM4T 3000	3000	45	45
DM4T 3500	3500	50	50
DM4T 4000	4000	50	50